

# Rittal – The System.

Faster – better – everywhere.



## SZ 2423.000

## Spacer

State: 5/13/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2423.000 - Spacer for roof plate

For raising the roof for ventilation purposes, available in three different heights. Not suitable for crane transport.

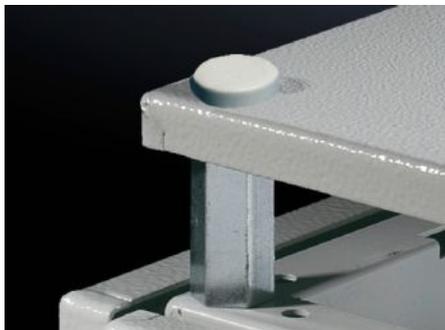

## Features

Model No.	SZ 2423.000
Product description	For raising the roof for ventilation purposes, available in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly components
Mounting tip	Not suitable for crane transportation
Dimensions	Height: 20 mm Height: 0.79 "
Dimensions	Thread: M12
Suitable for	Enclosure type: VX TS
Packaging unit	4 pc(s).
Net weight	0.216 kg
Gross weight	0.255 kg
PCF/VE (cradle-to-gate)	1 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared

# Features

---

Customs tariff number	73269098
ETIM 9	EC002625
ETIM 8	EC002625
ECLASS 8.0	27189234
Product description	SZ spacer, for VX, TS roof plate, H: 20 mm

---