


Rittal – The System.

Faster – better – everywhere.

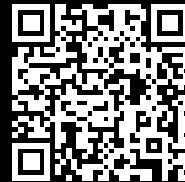

SZ 2560.010

Plastic cable gland plates

State: 12/8/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2560.010 - Plastic cable gland plates with metric knockouts

With pre-punched holes for cable glands.

Features

Model No.	SZ 2560.010
Product description	With pre-punched holes for cable glands. Used with standard flange plate seal.
Color	RAL 7035
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	2 x M12 2 x M20 3 x M25
Dimensions	Width: 160 mm Depth: 70 mm Width: 6.3 " Depth: 2.76 "
Suitable for	Enclosure type: AE
Gland plate	Size: 1
Operating temperature range	-40 °C...70 °C -40 °F...158 °F
Protection category IP to EN 60529	IP 55 if correctly installed
Number knockouts	2 2 3
Metric diameter	M12 M20 M25
Packaging unit	10 pc(s).

Features

Net weight	0.51
Gross weight	0.605
Customs tariff number	39269097
EAN	4028177550254
E-Number Sweden	E3404761
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421