


Rittal – The System.

Faster – better – everywhere.

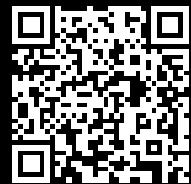

SZ 2564.300

Plastic Cable Gland Plates

State: 1/29/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2564.300 - Plastic Cable Gland Plates with diaphragms, for AX

Simply pierce the plastic with a sharp object, and pull through the cable.

Features

| | |
|--|---|
| Model No. | SZ 2564.300 |
| Product description | Just pierce the plastic with a sharp point and pull the cable through. |
| Material | Plastic to UL 94-V0 |
| Color | Similar to RAL 7035 |
| Note | The assignment of the flange plate size can be found on the respective housings |
| Dimensions | Width: 534 mm Depth: 149 mm Width: 21 " Depth: 5.87 " |
| Suitable for | Enclosure type: AX |
| Gland plate | Size: 4 |
| Protection category IP to EN 60 529 | IP 66 if correctly installed |
| Type rating according to UL 50E | Type 1 Type 12 |
| Quantity of cable entries and Ø (mm) min.-max. | 28 x 5-11 48 x 10-15 8 x 15-25 2 x 19-34 2 x 26-35 2 x 26-54 1 x 50-110 |
| Packaging unit | 1 pc(s). |
| Net weight | 0.7 |

Features

| | |
|-----------------------|---------------|
| Gross weight | 0.736 |
| Customs tariff number | 39269097 |
| EAN | 4028177935723 |
| E-Number Sweden | E3465291 |
| ETIM 9 | EC000211 |
| ETIM 8 | EC000211 |
| ECLASS 8.0 | 27142421 |

Approvals

Approvals UL + C-UL - FTTA