

# Rittal – The System.

Faster – better – everywhere.



## SZ 2565.200

State: 4/25/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2565.200 - with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).

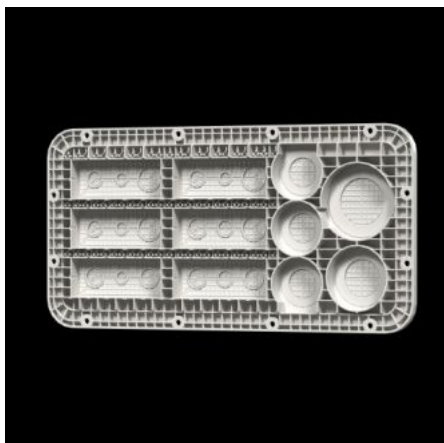

## Features

Model No.	SZ 2565.200
Product description	Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).
Material	Plastic to UL 94-V0
Color	RAL 7035
Number of rectangular cutouts information	1x rectangular cutout takes 10 sealing inserts, small
Number of rectangular cutouts	5
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	4 x M12 4 x M16 4 x M20 3 x M25 1 x M32 1 x M40

# Features

---

Dimensions	Width: 301 mm Depth: 221 mm Width: 11.9 " Depth: 8.7 "
Suitable for	Enclosure type: AX
Gland plate	Size: 5
Operating temperature range	-40 °C...80 °C -40 °F...176 °F
Protection category IP to EN 60529	IP 66 if correctly installed
Type rating according to UL 50E	Type 1 Type 12
Packaging unit	1 pc(s).
Net weight	0.4 kg
Gross weight	0.418 kg
Customs tariff number	39269097
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Plastic gland plates, for AX, for cable entry, modular, pre-punched, WD: 301x221 mm, for gland plates size 5

# Approvals

---

Approvals	UL + C-UL - FTTA
-----------	------------------