


Rittal – The System.

Faster – better – everywhere.

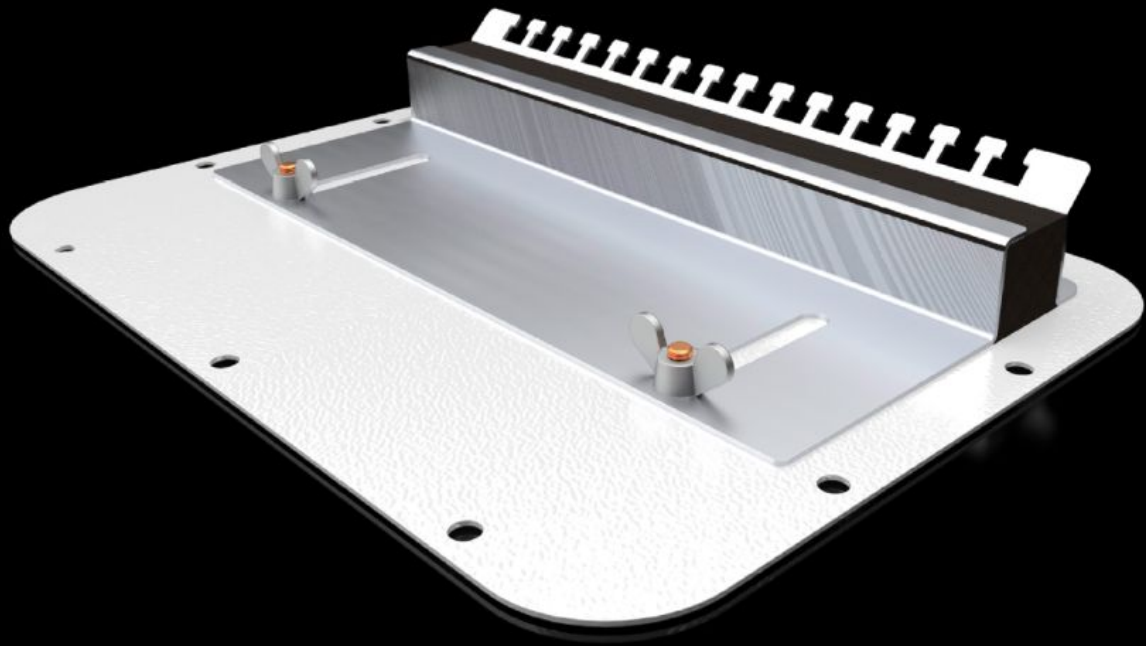

SZ 2565.400 Gland plate

State: 6/21/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2565.400 - Gland plate with elastic cable clamp strip, for AX

For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip.

Features

Model No.	SZ 2565.400
Product description	For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip.
Material	Gland plate: Carbon steel
Color	RAL 7035
Dimensions	Width: 301 mm Depth: 221 mm Width: 11.9 " Depth: 8.7 "
Suitable for	Enclosure type: AX
Gland plate	Size: 5
Packaging unit	1 pc(s).
Net weight	1.31 kg
Gross weight	1.34 kg
Customs tariff number	73079100
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Metal gland plate, for AX, with rubber cable clamp strip, WD: 301x221 mm, for gland plates size 5