
 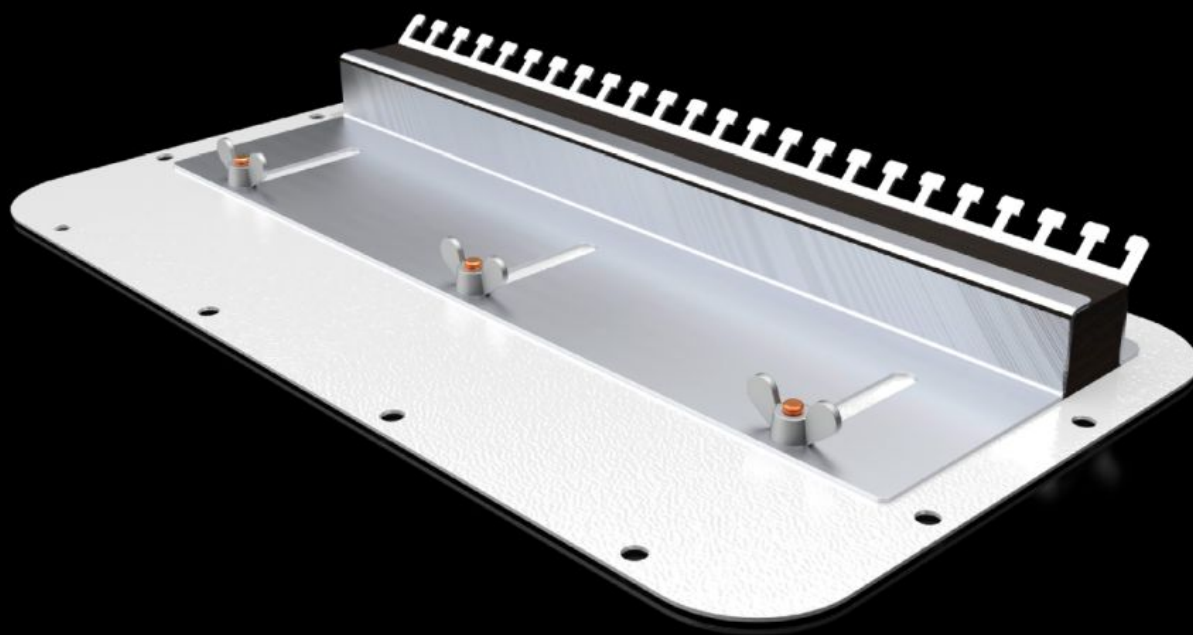


Rittal – The System.

Faster – better – everywhere.



SZ 2566.400 Gland plate

State: 6/24/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2566.400 - Gland plate with elastic cable clamp strip, for AX

For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip.

Features

| | |
|-----------------------|--|
| Model No. | SZ 2566.400 |
| Product description | For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip. |
| Material | Gland plate: Carbon steel |
| Color | RAL 7035 |
| Dimensions | Width: 401 mm Depth: 221 mm Width: 15.8 " Depth: 8.7 " |
| Suitable for | Enclosure type: AX |
| Gland plate | Size: 6 |
| Packaging unit | 1 pc(s). |
| Net weight | 1.65 |
| Gross weight | 1.84 |
| Customs tariff number | 94039910 |
| EAN | 4028177944619 |
| ETIM 9 | EC000211 |
| ETIM 8 | EC000211 |
| ECLASS 8.0 | 27142421 |