


# Rittal – The System.

Faster – better – everywhere.

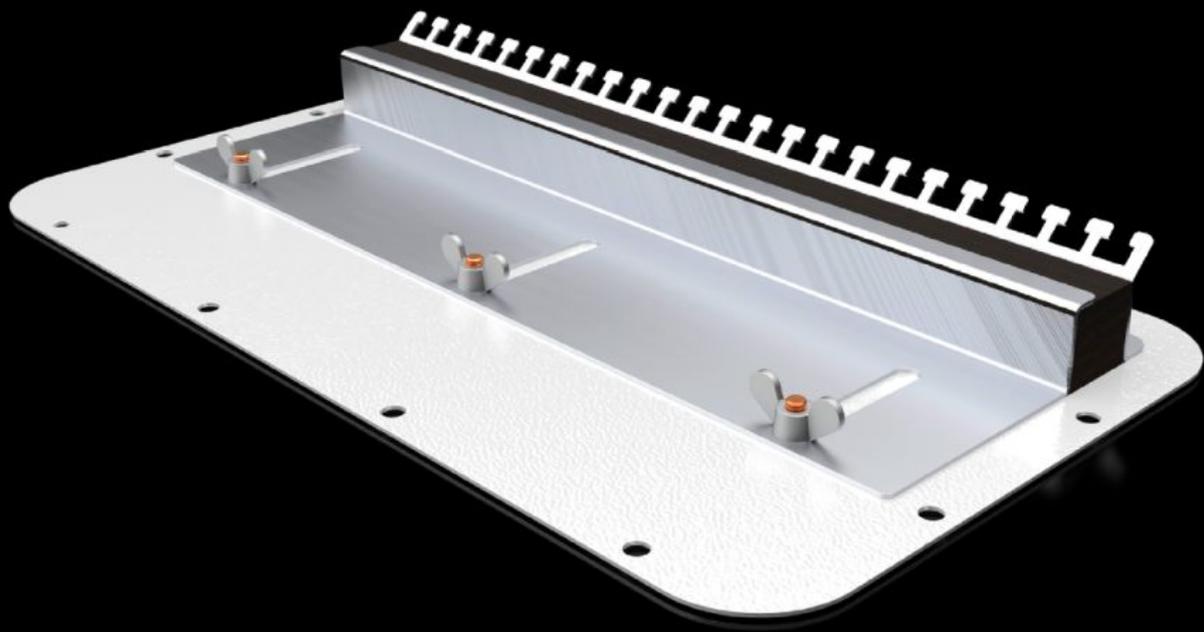

## SZ 2566.400 Gland plate

State: 4/25/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2566.400 - Gland plate with elastic cable clamp strip, for AX

For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip.

## Features

Model No.	SZ 2566.400
Product description	For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip.
Material	Gland plate: Carbon steel
Color	RAL 7035
Dimensions	Width: 401 mm Depth: 221 mm Width: 15.8 " Depth: 8.7 "
Suitable for	Enclosure type: AX
Gland plate	Size: 6
Packaging unit	1 pc(s).
Net weight	1.65 kg
Gross weight	1.84 kg
Customs tariff number	73079100
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Metal gland plate, for AX, with rubber cable clamp strip, WD: 401x221 mm, for gland plates size 6