


Rittal – The System.

Faster – better – everywhere.

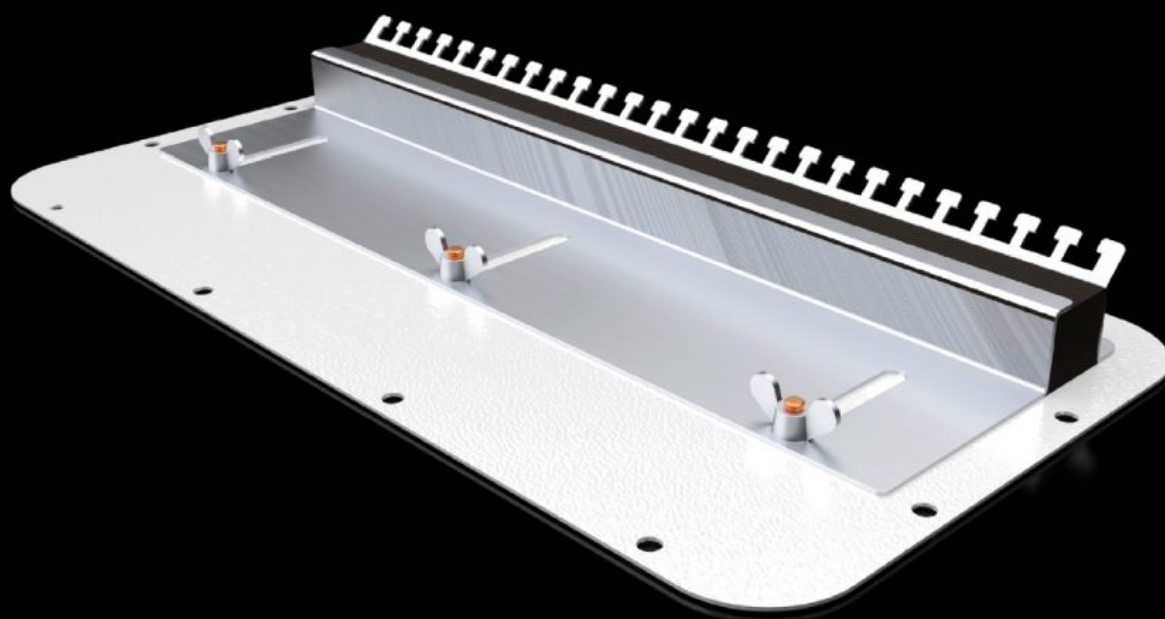

SZ 2567.400 Gland plate

State: 12/9/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2567.400 - Gland plate with elastic cable clamp strip, for AX

For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip.

Features

Model No.	SZ 2567.400
Product description	For feeding through pre-fabricated cables when the gland plate has already been fitted to the enclosure. Split gland plates can be sealed using movable plates with a foam rubber cable clamp strip.
Material	Gland plate: Carbon steel
Color	RAL 7035
Dimensions	Width: 436 mm Depth: 221 mm Width: 17.2 " Depth: 8.7 "
Suitable for	Enclosure type: AX
Gland plate	Size: 7
Packaging unit	1 pc(s).
Net weight	2
Gross weight	2.034
Customs tariff number	73079100
EAN	4028177944718
E-Number Sweden	E3465304
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421