


Rittal – The System.

Faster – better – everywhere.

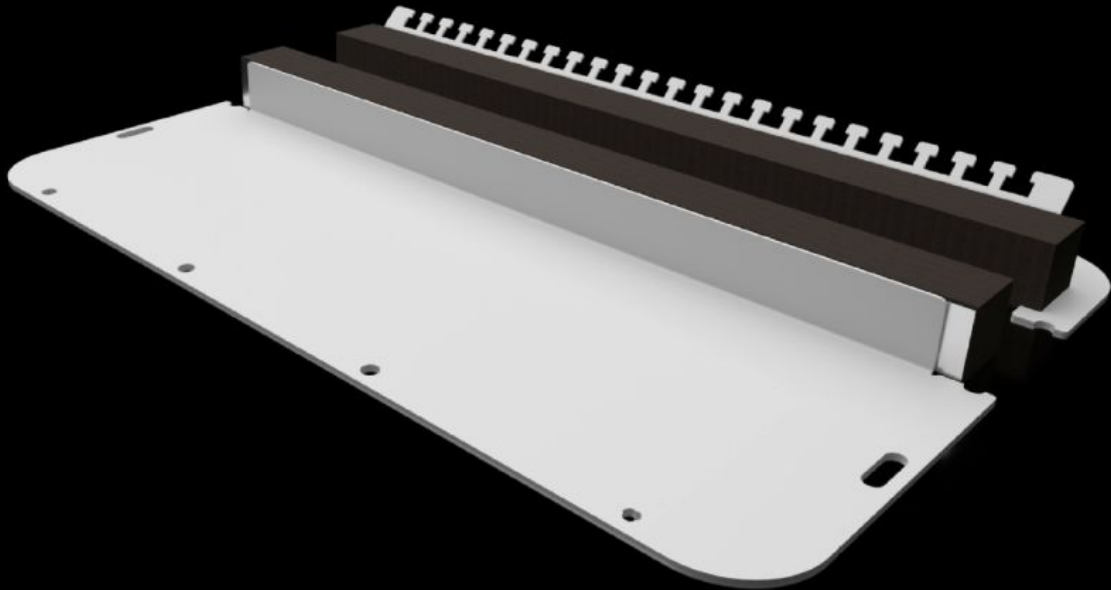

SZ 2567.450

Flange plate in two parts with elastic clamping profile

State: 7/8/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2567.450 - Flange plate in two parts with elastic clamping profile for AX

The split flange plate allows easy mounting on the housing and offers various installation options. For easy insertion of cables with or without plug connections into the housing. The special holes in the flange plate ensure automatic equipotential bonding when screwed together. Bolts, clamps or grounding cables are no longer necessary.

Features

| | |
|------------------------|---|
| Model No. | SZ 2567.450 |
| Version | Two-piece |
| Material | Carbon steel |
| Color | RAL 7035 |
| Supply includes | Assembly components |
| Note | The assignment of the flange plate size can be found on the respective housings When installing in enclosure width >760 mm, 2 PUs are required |
| Dimensions | Width: 436 mm Depth: 221 mm Width: 17.2 " Depth: 8.7 " |
| Suitable for | Enclosure type: AX |
| Suitable for Model No. | 1260.000 1339.000 1360.000 1376.000 1059.000 1091.000 1116.000 1261.000 |
| Gland plate | Size: 7 |
| Packaging unit | 1 pc(s). |

Features

| | |
|-------------------------------------|--|
| Net weight | 1.4 kg |
| Gross weight | 1.46 kg |
| PCF/VE (cradle-to-gate) | 5.6 kg CO2 eq (Cat B) |
| Information regarding the PCF class | Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared |
| Customs tariff number | 73079100 |
| ETIM 9 | EC000211 |
| ETIM 8 | EC000211 |
| ECLASS 8.0 | 27142421 |
| Product description | SZ metal flange plate in two parts, for AX, with elastic clamping profile, WD: 436x221 mm, for flange plates size 7 |