


Rittal – The System.

Faster – better – everywhere.

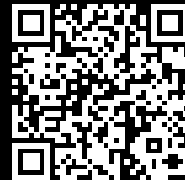

AX 2571.100 Metal gland plate

State: 7/13/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AX 2571.100 - Metal gland plate with metric knockouts, for AX

Simply knock out the holes for the cable glands with a screwdriver.

Features

Model No.	AX 2571.100
Product description	Simply knock out the holes for the cable glands with a screwdriver.
Material	Carbon steel
Color	RAL 7035
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	2 x M12 2 x M16 9 x M20 5 x M25 1 x M32 1 x M40
Dimensions	Width: 256 mm Depth: 149 mm Width: 10.1 " Depth: 5.87 "
Suitable for	Enclosure type: AX
Gland plate	Size: 1
Protection category IP to EN 60 529	IP 66 if correctly installed
Type rating according to UL 50E	Type 1 Type 12K

Features

Number knockouts	2
	2
	9
	5
	1
	1
Metric diameter	M12
	M16
	M20
	M25
	M32
	M40
Packaging unit	1 pc(s).
Net weight	0.46
Gross weight	0.469
PCF/VE (cradle-to-gate)	2.3 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73269098
EAN	4028177925304
E-Number Sweden	E3465295
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------