


Rittal – The System.

Faster – better – everywhere.

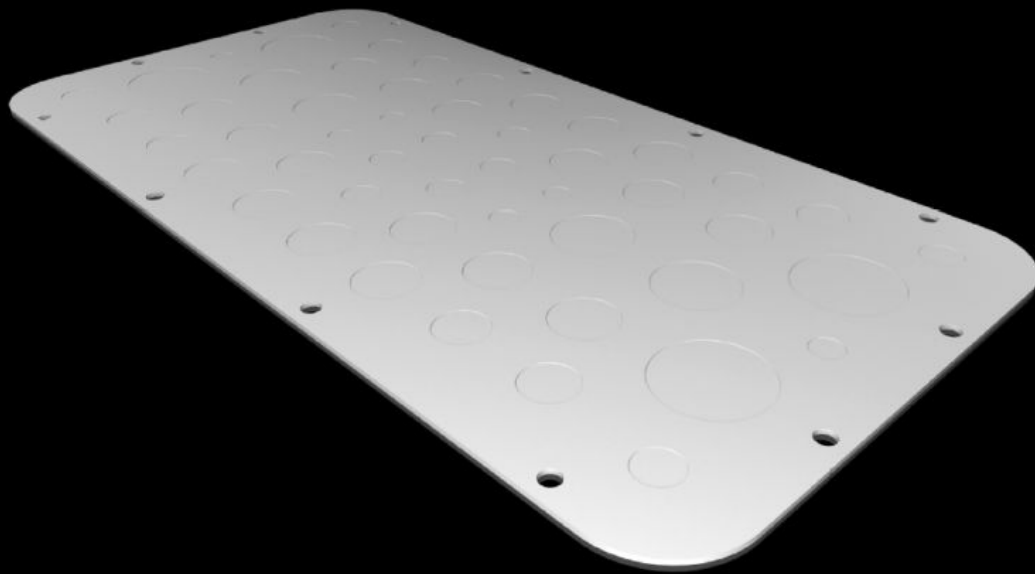

AX 2577.100 Metal gland plate

State: 6/16/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AX 2577.100 - Metal gland plate with metric knockouts, for AX

Simply knock out the holes for the cable glands with a screwdriver.

Features

| | |
|-------------------------------------|---|
| Model No. | AX 2577.100 |
| Product description | Simply knock out the holes for the cable glands with a screwdriver. |
| Material | Carbon steel |
| Color | RAL 7035 |
| Note | The assignment of the flange plate size can be found on the respective housings |
| No. of metric knockouts | 6 x M12 10 x M16 8 x M20 20 x M25 4 x M32 4 x M40 |
| Dimensions | Width: 436 mm Depth: 221 mm Width: 17.2 " Depth: 8.7 " |
| Suitable for | Enclosure type: AX |
| Gland plate | Size: 7 |
| Protection category IP to EN 60 529 | IP 66 if correctly installed |
| Type rating according to UL 50E | Type 1 Type 12K |
| Packaging unit | 1 pc(s). |
| Net weight | 1.136 kg |
| Gross weight | 1.146 kg |

Features

| | |
|-------------------------------------|--|
| PCF/VE (cradle-to-gate) | 5.9 kg CO2 eq (Cat B) |
| Information regarding the PCF class | Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared |
| Customs tariff number | 73079100 |
| ETIM 9 | EC000211 |
| ETIM 8 | EC000211 |
| ECLASS 8.0 | 27142421 |
| Product description | SZ Metal gland plate, for AX, with metric knockouts, WD: 436x221 mm, for gland plates size 7 |

Approvals

| | |
|-----------|------------------|
| Approvals | UL + C-UL - FTTA |
|-----------|------------------|