
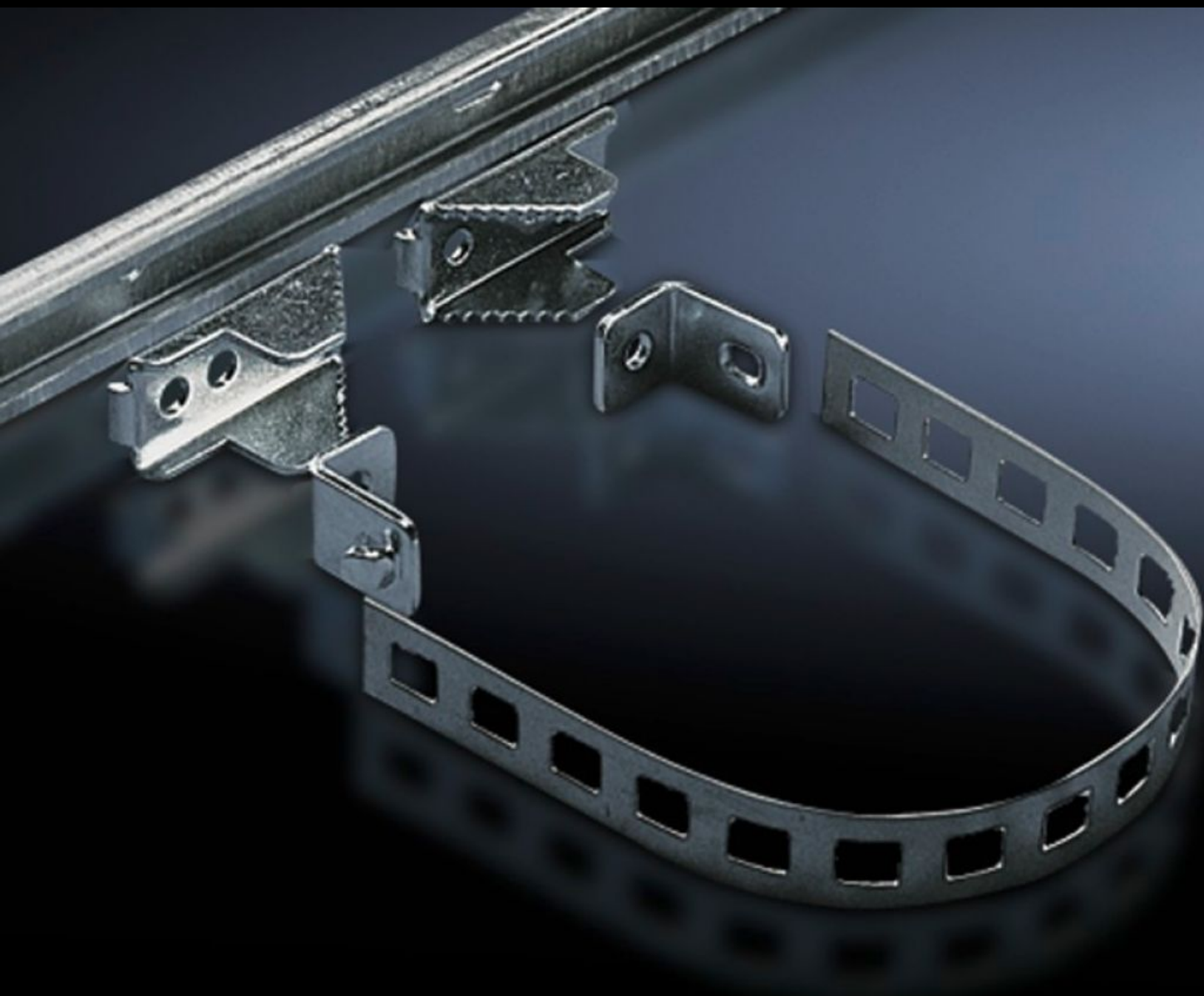


Rittal – The System.

Faster – better – everywhere.

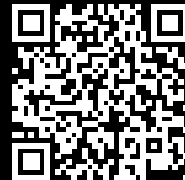

SZ 2584.000

Pole clamp

State: 5/13/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2584.000 - Pole clamp for KL, EB, BG, AE, KS and CS wall-mounted enclosures

For reliable, convenient fastening to round or square poles.



Features

Model No.	SZ 2584.000
Product description	For reliable, convenient fastening to round or square poles.
Applications	For pole diameter: Ø from 40 to 190 mm For pole size: □ from 50 to 150 mm
Material	Profile rails, clamping section: Carbon steel Clamping strap: Stainless steel 1.4301 (AISI 304)
Surface finish	Profile rail, clamping section: Zinc-plated
Supply includes	2 profile rails, 600 mm long 2 clamping straps 4 clamping brackets 4 screws and captive nuts M8 for mounting on the enclosure. 4 clamping sections
Installation options	Designed for 600 mm wide enclosures The pole clamp can be fitted to larger or smaller housings by shortening the rails or drilling additional holes in the housing
Packaging unit	2 pc(s).
Net weight	1.78
Gross weight	1.88
Customs tariff number	73182900

Features

EAN	4028177028760
E-Number Sweden	E3404516
ETIM 9	EC002625
ETIM 8	EC002625
ECLASS 8.0	27189234