


Rittal – The System.

Faster – better – everywhere.

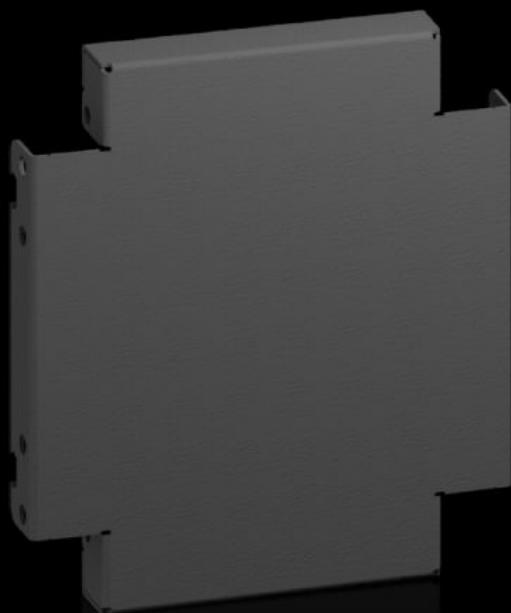

AX 2820.320

**Base/plinth trim panels, side, 200
mm**

State: 1/30/2026 (Source: rittal.com/us-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

AX 2820.320 - Base/plinth trim panels, side, 200 mm for AX

For completing a base/plinth unit at the sides and for additional stability, or the interior installation of bayed base/plinths. Either one 200 mm high or two 100 mm high trim panels can optionally be used to 200 mm high base/plinths.

Features

Model No.	AX 2820.320
Product description	For completing a base/plinth unit at the sides and for additional stability, or the interior installation of bayed base/plinths. Either one 200 mm high or two 100 mm high trim panels can optionally be used to 200 mm high base/plinths.
Material	Carbon steel
Color	RAL 9005
Supply includes	Assembly components
Note	The components of the first generation base/plinth system cannot be combined with the components of the second generation base/plinth system
Dimensions	Height: 200 mm Height: 7.87 "
Suitable for	Depth: = 300 mm Depth: = 11.8 "
Packaging unit	2 pc(s).
Net weight	1
Gross weight	1.14
Customs tariff number	94039910
EAN	4028177942646
ETIM 9	EC000721
ETIM 8	EC000721

Features

ECLASS 8.0

27182003