
 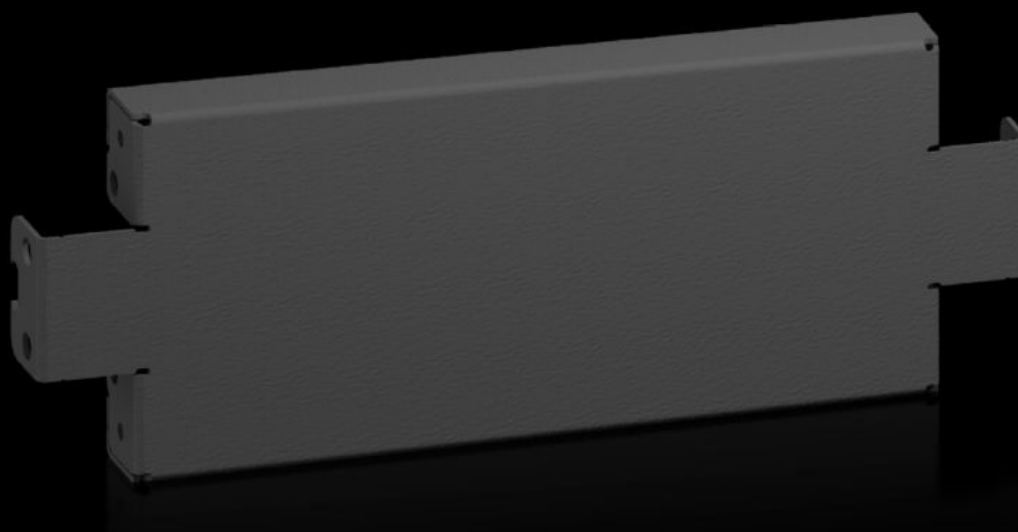


# Rittal – The System.

Faster – better – everywhere.



## AX 2820.410

## Base/plinth trim panels, side, 100 mm

State: 5/14/2024 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AX 2820.410 - Base/plinth trim panels, side, 100 mm for AX

For side completion of a base/plinth unit and for additional stabilization or the interior installation of baying bases. One 200 mm high or two 100 mm high trim panels can optionally be used to 200 mm high base/plinths.

## Features

Model No.	AX 2820.410
Product description	For side completion of a base/plinth unit and for additional stabilization or the interior installation of baying bases. One 200 mm high or two 100 mm high trim panels can optionally be used to 200 mm high base/plinths.
Material	Carbon steel
Color	RAL 9005
Supply includes	Assembly components
Dimensions	Height: 100 mm Height: 3.94 "
Suitable for	Depth: = 400 mm Depth: = 15.7 "
Type rating according to UL 50E	Type 1, 3R, 4, 12
Packaging unit	2 pc(s).
Weight/packaging unit	0.53 kg 1.2 lb.
Customs tariff number	94039910
EAN	4028177942530
ETIM 8	EC000721
ETIM 7.0	EC000721
ECLASS 8.0	27182003

# Approvals

---

Approvals

UL + C-UL - FTTA