

Rittal – The System.

Faster – better – everywhere.



SV 3052.000

Busbar Supports

State: 2/17/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 3052.000 - Busbar Supports

For 1250 A (100 mm), 1600 A (185 mm), 2500 A (150 mm), 3000 A (150 mm) busbar systems.

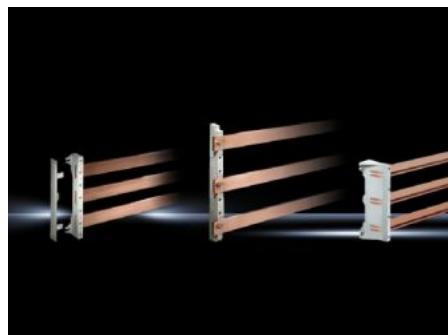

Features

Model No.	SV 3052.000
Material	Fiberglass-reinforced, thermoplastic polyester (PBT) Fire protection corresponding to UL 94-V0
Color	RAL 7035
Number of poles	3-pole 185 mm
Suitable for busbars	50 x 10 60 x 10 80 x 10
Rated current max.	1,600 A
Note on Model No.:	The base component of the busbar support may also be used as a single-pole support.
Dimensions	Width: 24 mm Height: 515 mm Depth: 51 mm Width: 0.94 “ Height: 20.3 “ Depth: 2.01 “
Packaging unit	2 pc(s).
Net weight	1.26
Gross weight	1.338

Features

Customs tariff number 85369010

EAN 4028177035751

ETIM 9 EC001166

ETIM 8 EC001166

ECLASS 8.0 27400607

Approvals

Approvals ABS

Explanations Declaration of conformity
Declaration of conformity UK