

Rittal – The System.

Faster – better – everywhere.



SK 3108.024 Enclosure internal fan

State: 5/12/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 3108.024 - Enclosure internal fan

To prevent hot spots inside the enclosure and facilitate the ventilation of active enclosure climate control components.

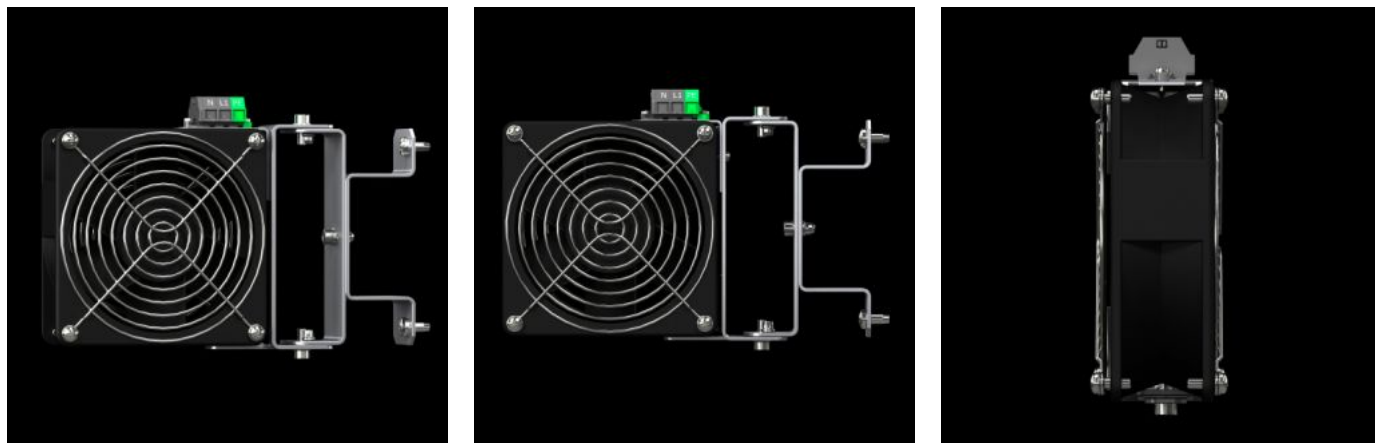

Features

Model No.	SK 3108.024
Product description	To prevent hot-spots and support the air routing of active enclosure climate control components. Adjustable in two axes. Mounted on the frame section. Several fans can be cascaded using the quick-release terminal strip.
Supply includes	Complete unit ready for connection with axial fan Snap-on pivot device Fasteners
Rated operating voltage	24 V (DC)
Rated power P_{el}	with DC: 3.5 W
Rated current max.	with DC: 0.15 A
Packaging unit	1 pc(s).
Net weight	0.8 kg
Gross weight	0.978 kg
Customs tariff number	84145915
ETIM 9	EC000320
ETIM 8	EC000320

Features

ECLASS 8.0

27180716

Product description

SK enclosure internal fan, 3.5 W, 24 V (DC)

Approvals

Explanations

Declaration of conformity