
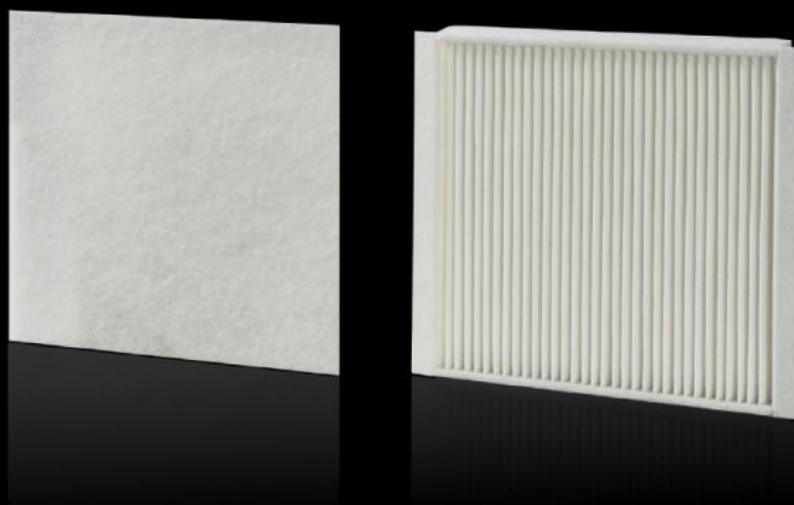


Rittal – The System.

Faster – better – everywhere.

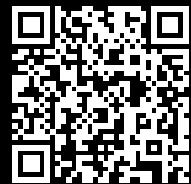

SK 3238.025

Pleated filter

State: 2/10/2026 (Source: rittal.com/us-en)



FRIEDHELM LOH GROUP

SK 3238.025 - Pleated filter for filter and roof-mounted fans, cooling units and chillers

Compared to conventional chopped fiber filters, the high-quality pleated filter technology enables a significant increase in the volume flow and thus an increase in the performance of the unit as well as a reduction in energy consumption. In addition, better filtration properties ensure less dust in the enclosure or unit, and the longer service life means significantly lower service costs.

Features

Model No.	SK 3238.025
Version	for fan-and-filter units / outlet filters
Material	Pleated filter: base polyester, meltblown polycarbonate Absorber mat: 100% polyester
Color	White
Note	Not suitable for use in EMC filter fans.
Suitable for Model No.	3238.3xx 3238.7xx
Dimensions	Width: 114 mm Height: 114 mm Depth: 14 mm Width: 4.49 " Height: 4.49 " Depth: 0.55 "
Absorber mat dimensions	Width: 120 mm Height: 120 mm
Protection category IP to IEC 60 529	IP 55 when mounted in filter fan/outlet filter
Packaging unit	5 pc(s).
Net weight	0.1
Gross weight	0.113
Customs tariff number	56039390

Features

EAN	4028177969117
ETIM 9	EC002513
ETIM 8	EC002513
ECLASS 8.0	27180706

Approvals

Approvals	UR + C-UR (recognized)
-----------	------------------------