


Rittal – The System.

Faster – better – everywhere.

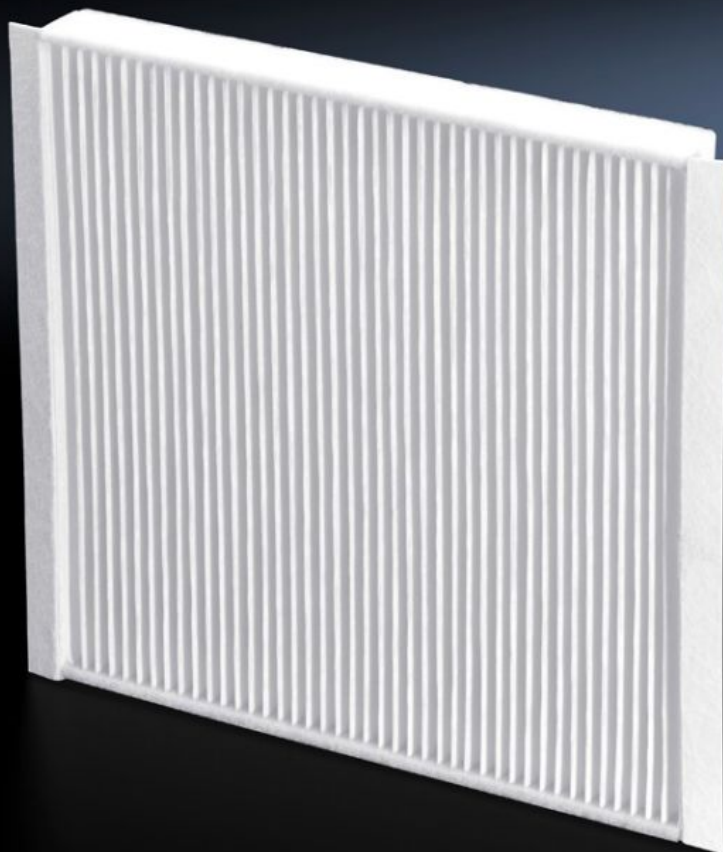

SK 3285.940 Pleated filter

State: 8/14/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 3285.940 - Pleated filter for filter and roof-mounted fans, cooling units and chillers

Compared to conventional chopped fiber filters, the high-quality pleated filter technology enables a significant increase in the volume flow and thus an increase in the performance of the unit as well as a reduction in energy consumption. In addition, better filtration properties ensure less dust in the enclosure or unit, and the longer service life means significantly lower service costs.

Features

Model No.	SK 3285.940
Version	for chillers
Material	Polyester
Note	Performance data, protection category, and device approvals are only guaranteed when used in conjunction with original Rittal filter mats.
Suitable for Model No.	3319.100 3320.200 3334.3x0 3334.4x0
Dimensions	Width: 131 mm Height: 113 mm Depth: 13 mm Width: 5.16 " Height: 4.45 " Depth: 0.51 "
Filter class	to DIN EN 779: G3
Packaging unit	3 pc(s).
Net weight	0.087
Gross weight	0.097
Customs tariff number	56039390
EAN	4028177924352
ETIM 9	EC002513

Features

ETIM 8	EC002513
ECLASS 8.0	27180706