

# Rittal – The System.

Faster – better – everywhere.



## SK 3327.700 Chopped fiber filter mat

State: 12/13/2025 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SK 3327.700 - Chopped fiber filter mat

Replacement filter mats for roof fans, filter fans or thermoelectric coolers to effectively protect control enclosure components from dirt, dust and water.

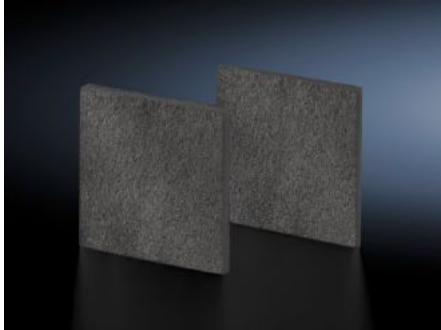

## Features

Model No.	SK 3327.700
Version	for filter fans
Product description	Made of chopped-fiber mat with a progressive construction. Temperature-resistant to 100 °C, self-extinguishing category F1 to DIN 53 438. Dust-laden air side: Open structure. Clean air side: Closed structure. Reliable filtering of virtually all types of dust from a particle size of 10 µm.
Material	Chemical fibers
Note	Performance data, protection category, and device approvals are only guaranteed when used in conjunction with original Rittal filter mats.
Filter class	to DIN EN 779: G3 to DIN EN ISO 16890: ISO coarse 50%
Packaging unit	5 pc(s).
Net weight	0.09
Gross weight	0.093
Customs tariff number	56039390
EAN	4028177205314
ETIM 9	EC002513

# Features

ETIM 8	EC002513
ECLASS 8.0	27180706

# Approvals

Certificates	EAC
--------------	-----