


# Rittal – The System.

Faster – better – everywhere.

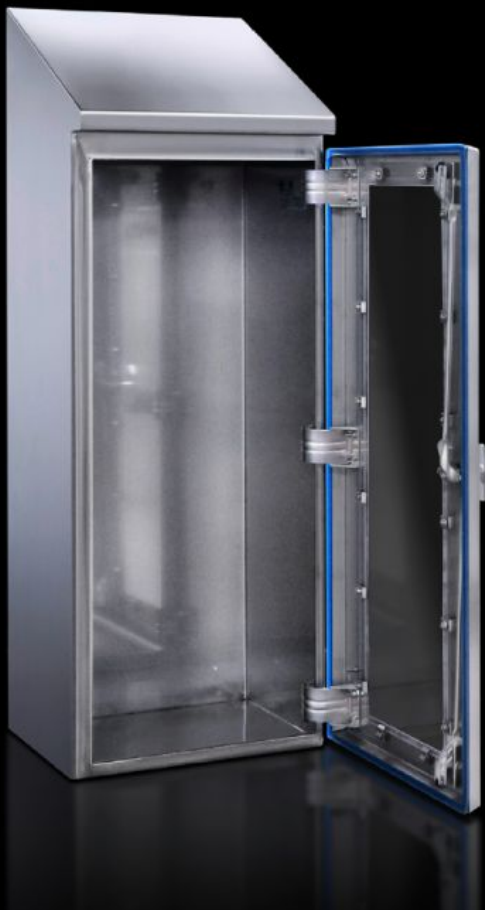

## HD 4000.075 Hygienic Design

State: 5/21/2024 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# HD 4000.075 - Hygienic Design Fire-extinguisher enclosure HD

Important safety equipment can be accessed quickly and is hygienically protected - the fire-extinguishing housing can be installed directly in the production environment

## Features

Model No.	HD 4000.075
Version	Roof slope 30° towards the front
Benefits	Hygienic storage of fire extinguishers, protected from hose water Time and cost savings due to simple and effective cleaning options Simple removal of fire extinguisher with one hand due to T-handle Quick inventory check through integrated viewing door
Material	Housing and door: Stainless steel 1.4301 (AISI 304) Handle and lock: Stainless steel 1.4301 (AISI 304) Viewing window: Polycarbonate Seal: Silicone, compliant with FDA Guideline 21 CFR 177.2600
Surface finish	Housing and door: Brushed, grain 400, peak-to-valley height < 0.8 µm Seal: Blue, dyed (RAL 5010)
Supply includes	Housing of all-round solid construction Door with viewing window and inserted seal Interchangeable door catch T-handle with 3-point locking system
Dimensions	Width: 390 mm Height, front: 840 mm Height rear: 1,010 mm Depth: 300 mm Width: 15.4 " Height, front: 33.1 " Height rear: 39.8 " Depth: 11.8 "

# Features

Visible area	Viewing window width: 190 mm Viewing window height: 670 mm Viewing window width: 7.48 “ Viewing window height: 26.4 “
Protection category IP to EN 60529	IP 66
Protection category IP69K	IP 59K
Packaging unit	1 pc(s).
Weight/packaging unit	22 kg 48.5 lb.
Customs tariff number	94032080
EAN	4028177918948
ETIM 7.0	EC000261
ECLASS 8.0	27180101