
 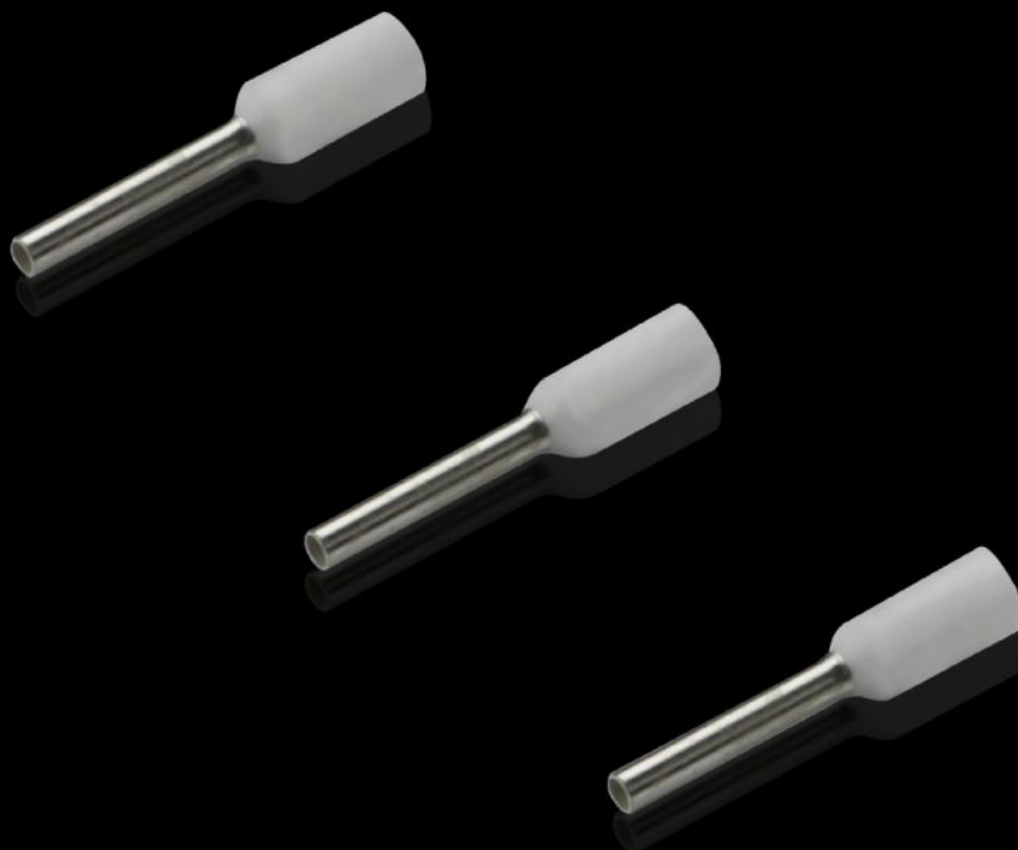


Rittal – The System.

Faster – better – everywhere.



AS 4050.730 Wire end ferrule

State: 5/16/2024 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.730 - Wire end ferrule Loose

With plastic collar.

Features

Model No.	AS 4050.730
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	White
Length	8 mm 0.31 ~
AWG	20
Internal diameter	2.6 mm 0.1 ~
For cross section	0.5 mm ²
DIN color code	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Suitable for Model No.	4051.205 4051.210 4050.452
Delivery form	Loose
Packaging unit	500 pc(s).
Weight/packaging unit	0.5 kg 1.1 lb.
Customs tariff number	85369010

Features

EAN	4028177804982
ETIM 7.0	EC000005
ECLASS 8.0	36659290

Approvals

Approvals	UL + C-UL (listed) UR
-----------	--------------------------