


**Rittal – The System.**

Faster – better – everywhere.

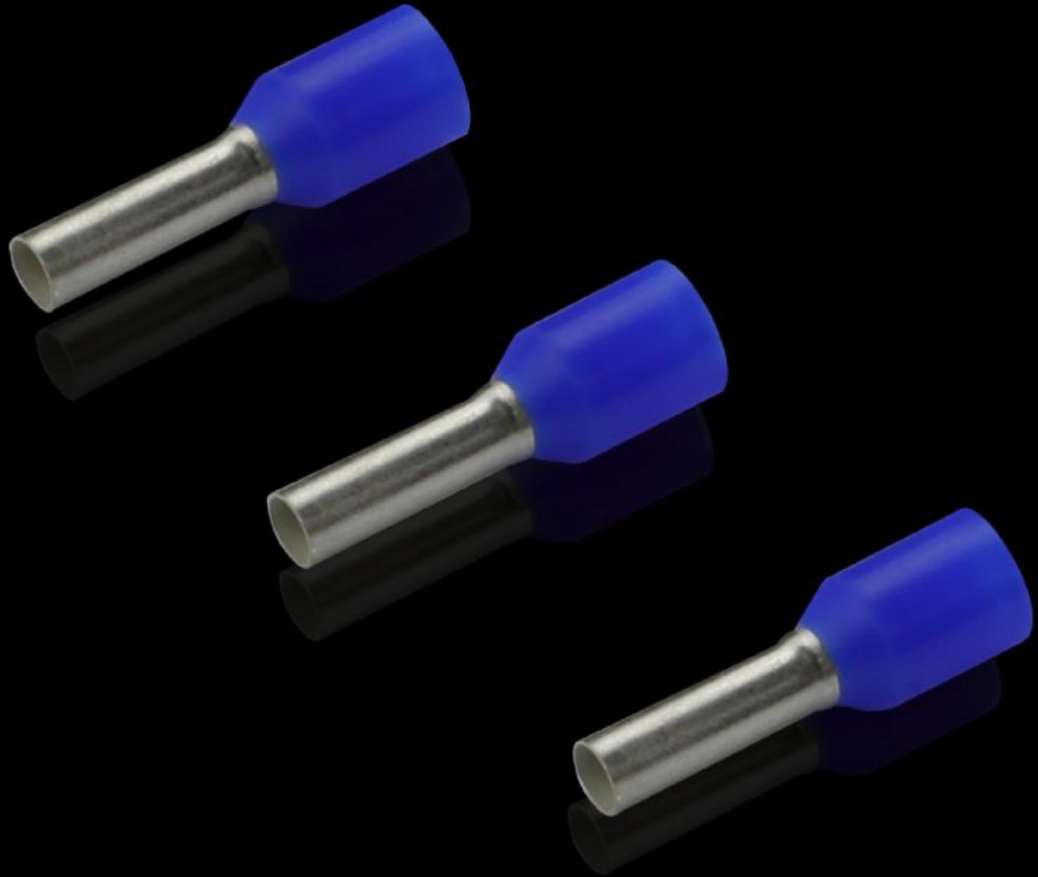

# AS 4050.734

## Wire end ferrule

State: 4/26/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.734 - Wire end ferrule Loose

With plastic collar.

## Features

Model No.	AS 4050.734
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Blue
Length	8 mm 0.31 "
AWG	14
Internal diameter	4.2 mm 0.17 "
For cross section	2.5 mm <sup>2</sup>
DIN color code	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Suitable for Model No.	4051.205 4051.210 4050.452
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5 kg
Customs tariff number	85369010
ETIM 9	EC000005

# Features

---

ETIM 8	EC000005
ECLASS 8.0	36659290
Product description	Wire end ferrules for wire assembly, 2.5 mm <sup>2</sup> , blue, loose, 8 mm

---

# Approvals

---

Approvals	UL + C-UL (listed) UR
-----------	--------------------------

---