


Rittal – The System.

Faster – better – everywhere.

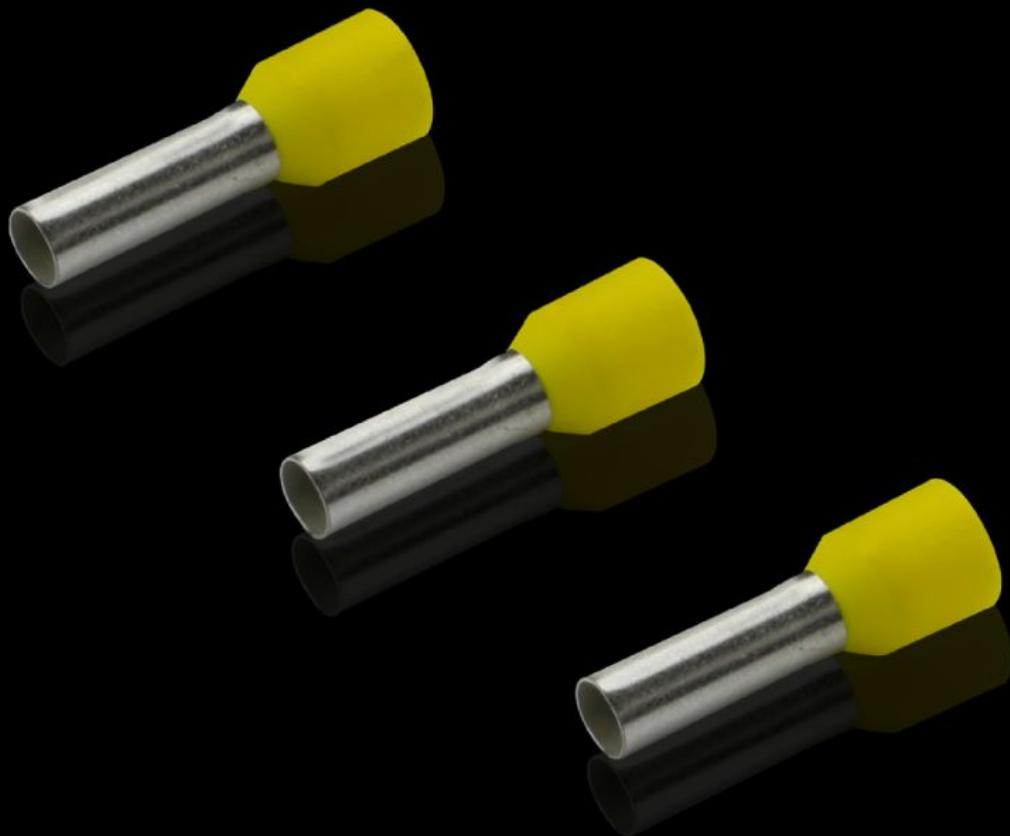

AS 4050.736

Wire end ferrule

State: 1/10/2026 (Source: rittal.com/us-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

AS 4050.736 - Wire end ferrule Loose

With plastic collar.

Features

| | |
|--------------------------|--|
| Model No. | AS 4050.736 |
| Product description | With plastic collar. |
| Technical specifications | Heat resistant up to 105 °C |
| Material | E-Cu, tin-plated Plastic collar: Polypropylene |
| Color | Yellow |
| Length | 12 mm 0.47 " |
| AWG | 10 |
| Internal diameter | 6.3 mm 0.25 " |
| For cross section | 6 mm ² |
| DIN color code | Yes |
| Note | UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative. |
| Standards | AEH DIN 46228 |
| Suitable for Model No. | 4051.210 |
| Delivery form | Loose |
| Packaging unit | 100 pc(s). |
| Net weight | 0.1 |
| Gross weight | 0.1 |
| Customs tariff number | 85369010 |
| EAN | 4028177805040 |

Features

ETIM 9 EC000005

ETIM 8 EC000005

ECLASS 8.0 36659290

Approvals

Approvals UL + C-UL (listed)
UR