


# Rittal – The System.

Faster – better – everywhere.

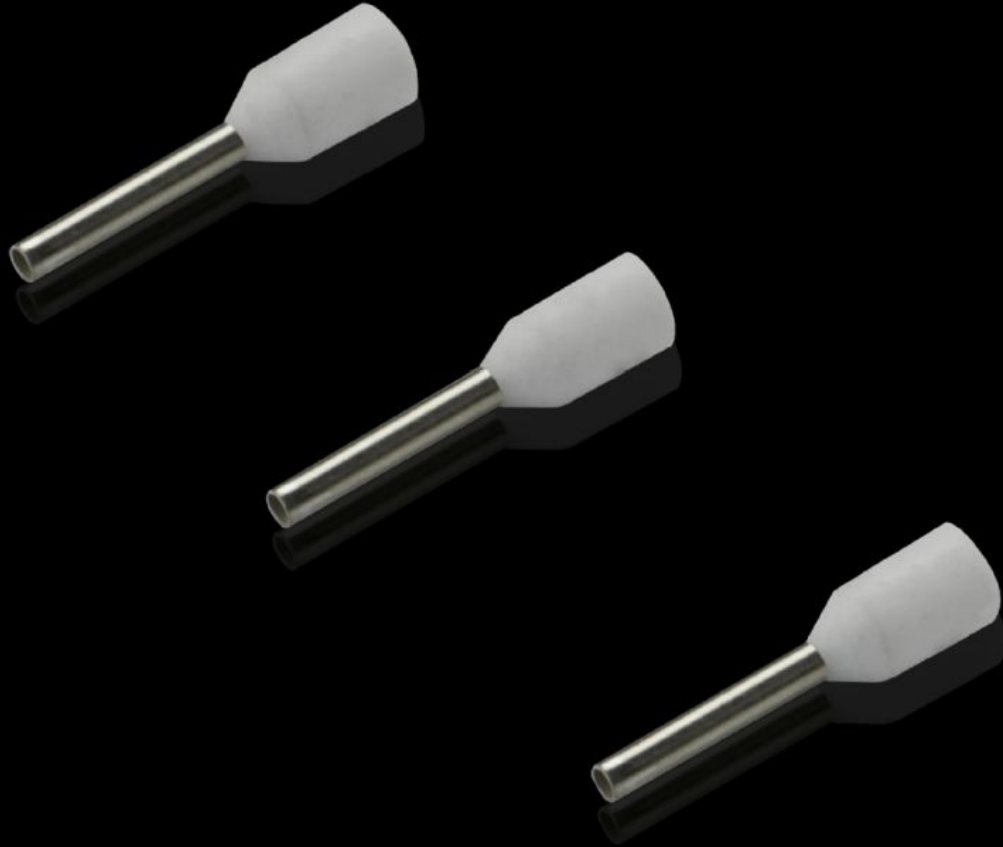

## AS 4050.742 Wire end ferrule

State: 7/9/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.742 - Wire end ferrule Loose

With plastic collar.

## Features

Model No.	AS 4050.742
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	White
Length	8 mm 0.31 "
AWG	20
Internal diameter	2.9 mm 0.11 "
For cross section	0.5 mm <sup>2</sup>
DIN color code	Yes
Multinorm	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5 kg
Gross weight	0.5 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005

# Features

---

ECLASS 8.0	36659290
Product description	Wire end ferrules for wire assembly, 0.5 mm <sup>2</sup> , AWG 20, white, loose, 8 mm (wide shaft)

---

# Approvals

---

Approvals	UL + C-UL (listed) UR
-----------	--------------------------