


Rittal – The System.

Faster – better – everywhere.

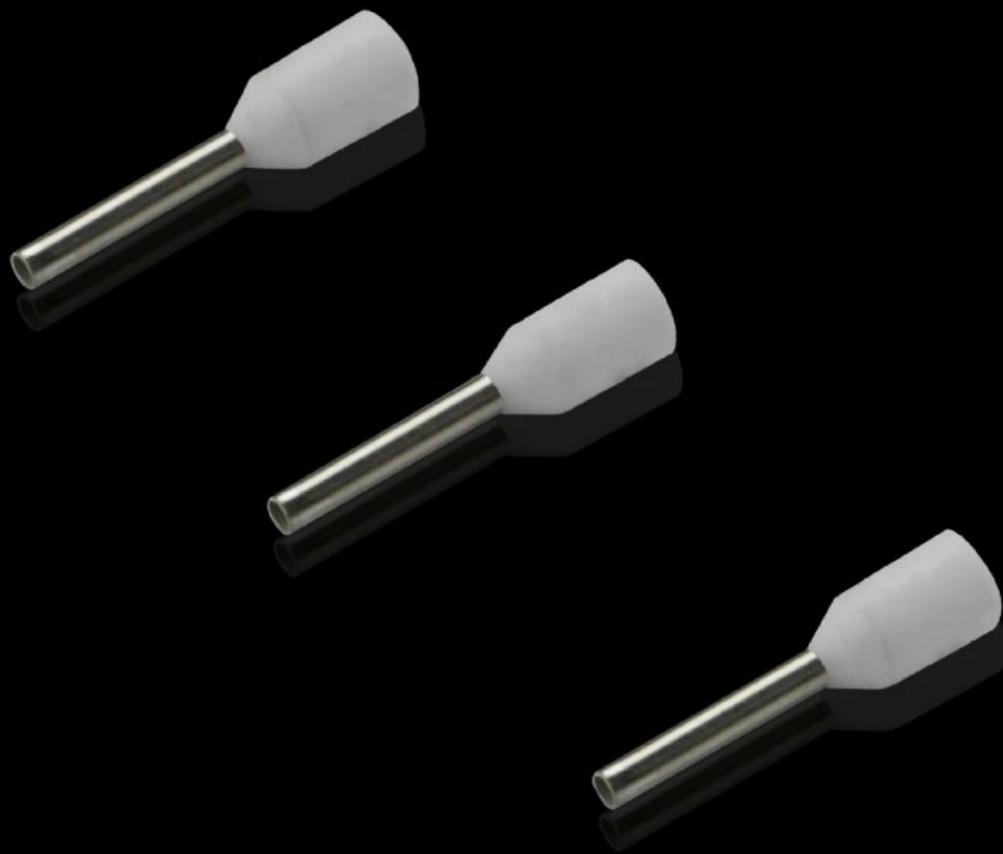

AS 4050.742

Wire end ferrule

State: 1/28/2026 (Source: rittal.com/us-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

AS 4050.742 - Wire end ferrule Loose

With plastic collar.

Features

Model No.	AS 4050.742
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	White
Length	8 mm 0.31 "
AWG	20
Internal diameter	2.9 mm 0.11 "
For cross section	0.5 mm ²
DIN color code	Yes
Multinorm	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Delivery form	Loose
Packaging unit	500 pc(s).
Net weight	0.5
Gross weight	0.5
Customs tariff number	85369010
EAN	4028177805101
ETIM 9	EC000005

Features

ETIM 8 EC000005

ECLASS 8.0 36659290

Approvals

Approvals UL + C-UL (listed)
UR