
 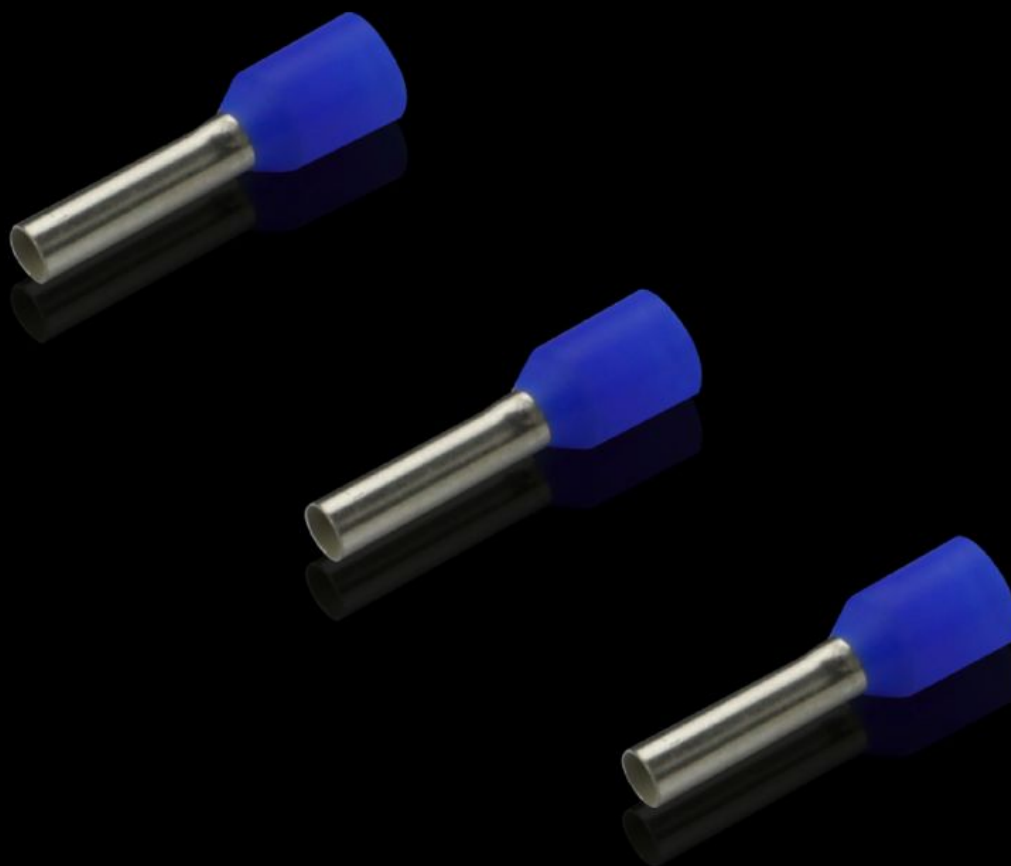


Rittal – The System.

Faster – better – everywhere.



AS 4051.525 Wire end ferrule

State: 9/14/2025 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4051.525 - Wire end ferrule Loose

With plastic collar.

Features

Model No.	AS 4051.525
Product description	With plastic collar.
Technical specifications	Heat resistant up to 105 °C
Material	E-Cu, tin-plated Plastic collar: Polypropylene
Color	Blue
Length	10 mm 0.39 ~
AWG	14
Internal diameter	4.2 mm 0.17 ~
For cross section	2.5 mm ²
DIN color code	Yes
Note	UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative.
Standards	AEH DIN 46228
Suitable for Model No.	4051.205 4051.210
Delivery form	Loose (10 packs of 100)
Packaging unit	1,000 pc(s).
Net weight	1
Gross weight	0.176
Customs tariff number	85369010

Features

EAN	4028177815834
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290

Approvals

Approvals	UL + C-UL (listed) UR
-----------	--------------------------