


Rittal – The System.

Faster – better – everywhere.

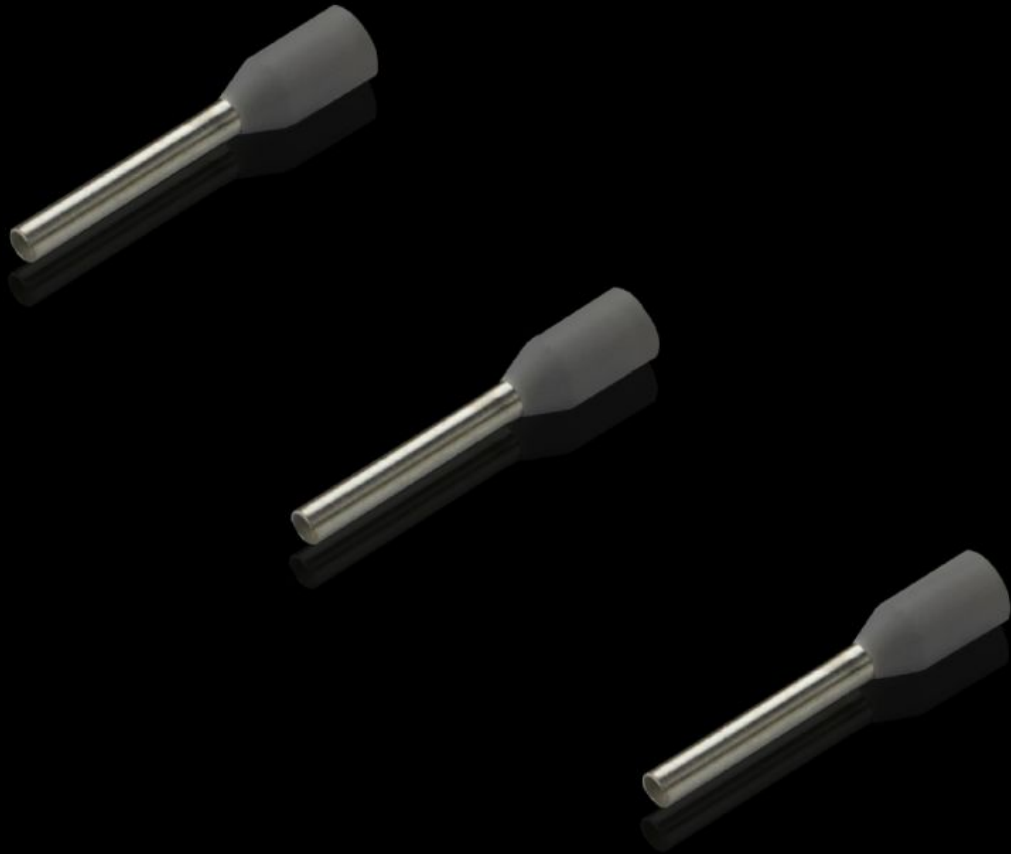

AS 4051.641 Wire end ferrule

State: 6/15/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4051.641 - Wire end ferrule Loose

With plastic collar.

Features

| | |
|--------------------------|--|
| Model No. | AS 4051.641 |
| Product description | With plastic collar. |
| Technical specifications | Heat resistant up to 105 °C |
| Material | E-Cu, tin-plated Plastic collar: Polypropylene |
| Color | Gray |
| Length | 10 mm 0.39 " |
| AWG | 18 |
| Internal diameter | 2.8 mm 0.11 " |
| For cross section | 0.75 mm ² |
| DIN color code | Yes |
| Note | UL-certified in conjunction with the relevant tools, e.g. crimping machines. For tailored advice, please contact a Rittal representative. |
| Standards | AEH DIN 46228 |
| Suitable for Model No. | 4051.205 4051.210 |
| Delivery form | Loose (10 packs of 100) |
| Packaging unit | 1,000 pc(s). |
| Net weight | 1 kg |
| Gross weight | 0.11 kg |
| Customs tariff number | 85369010 |

Features

| | |
|---------------------|--|
| ETIM 9 | EC000005 |
| ETIM 8 | EC000005 |
| ECLASS 8.0 | 36659290 |
| Product description | Wire end ferrules for wire assembly, 0.75 mm ² , AWG 18, grey, 10 mm, loose (10 packs of 100 pieces), 1000 pieces |

Approvals

| | |
|-----------|--------------------------|
| Approvals | UL + C-UL (listed) UR |
|-----------|--------------------------|