


Rittal – The System.

Faster – better – everywhere.

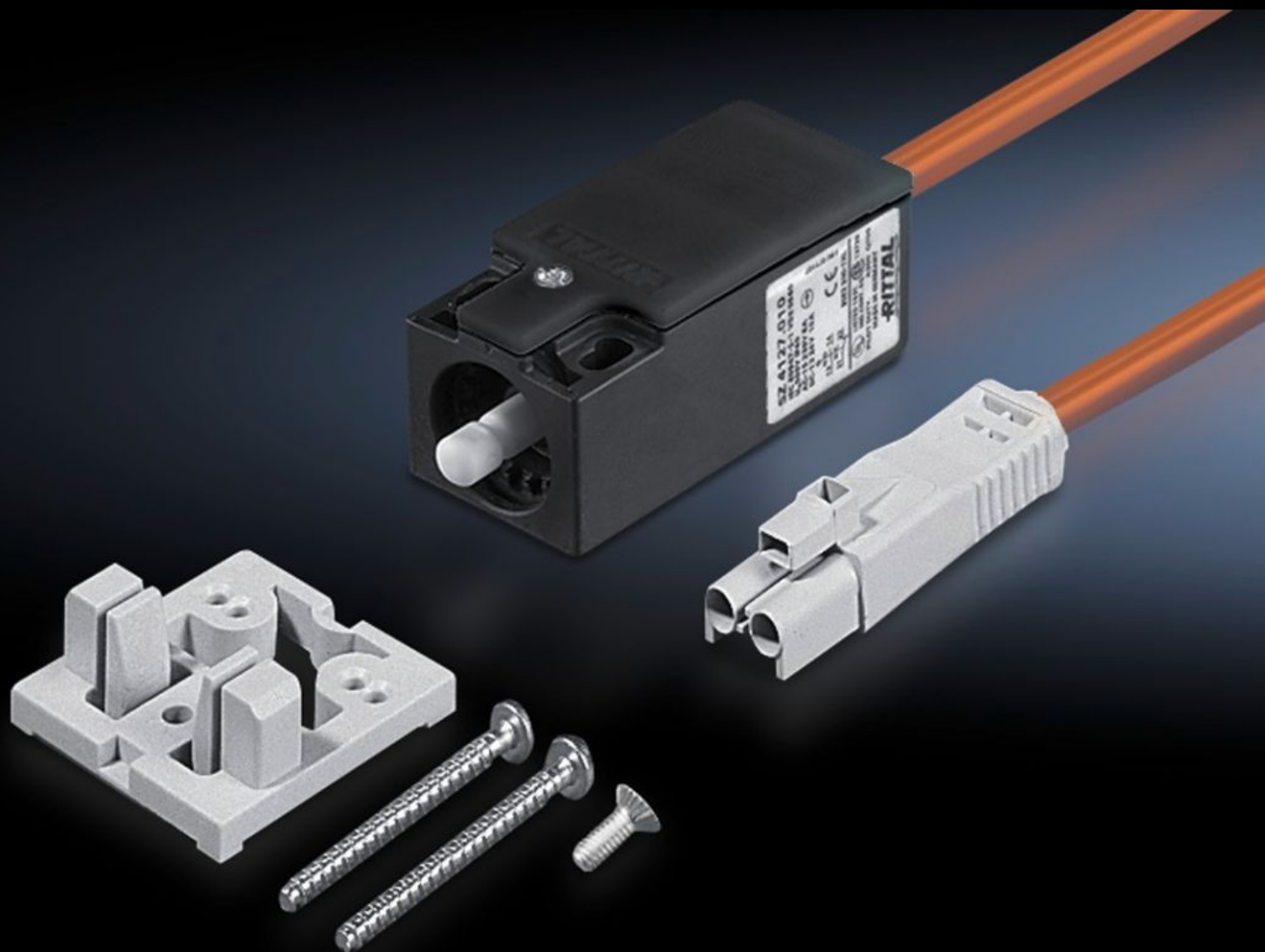

SZ 4315.550 Door-Operated Switch

State: 8/26/2025 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 4315.550 - Door-Operated Switch

With mounting accessories, with or without connection cable.

Features

Model No.	SZ 4315.550
Version	With connection cable
Length	600 mm 23.6 "
Rated impulse withstand voltage, phase to phase	6000 V AC
Rated insulation voltage	400 V AC
Installation options	for standard and courtesy lights without an integrated door-operated switch
Dimensions	Length: 600 mm Length: 23.6 "
Electrical connection	240 V AC/6 A 125 V DC/8 A 24 V AC/6 A 24 V DC/6 A
Rated operating voltage	400 V
Protection category IP to IEC 60529	IP 40
Packaging unit	1 pc(s).
Net weight	0.115
Gross weight	0.122
Customs tariff number	85365019
EAN	4028177501461
ETIM 9	EC002626
ETIM 8	EC002626

Features

ECLASS 8.0	27189266
------------	----------

Approvals

Approvals	CQC CQC-CCC CSA UL + C-UL (listed) UR
-----------	---