


**Rittal – The System.**

Faster – better – everywhere.

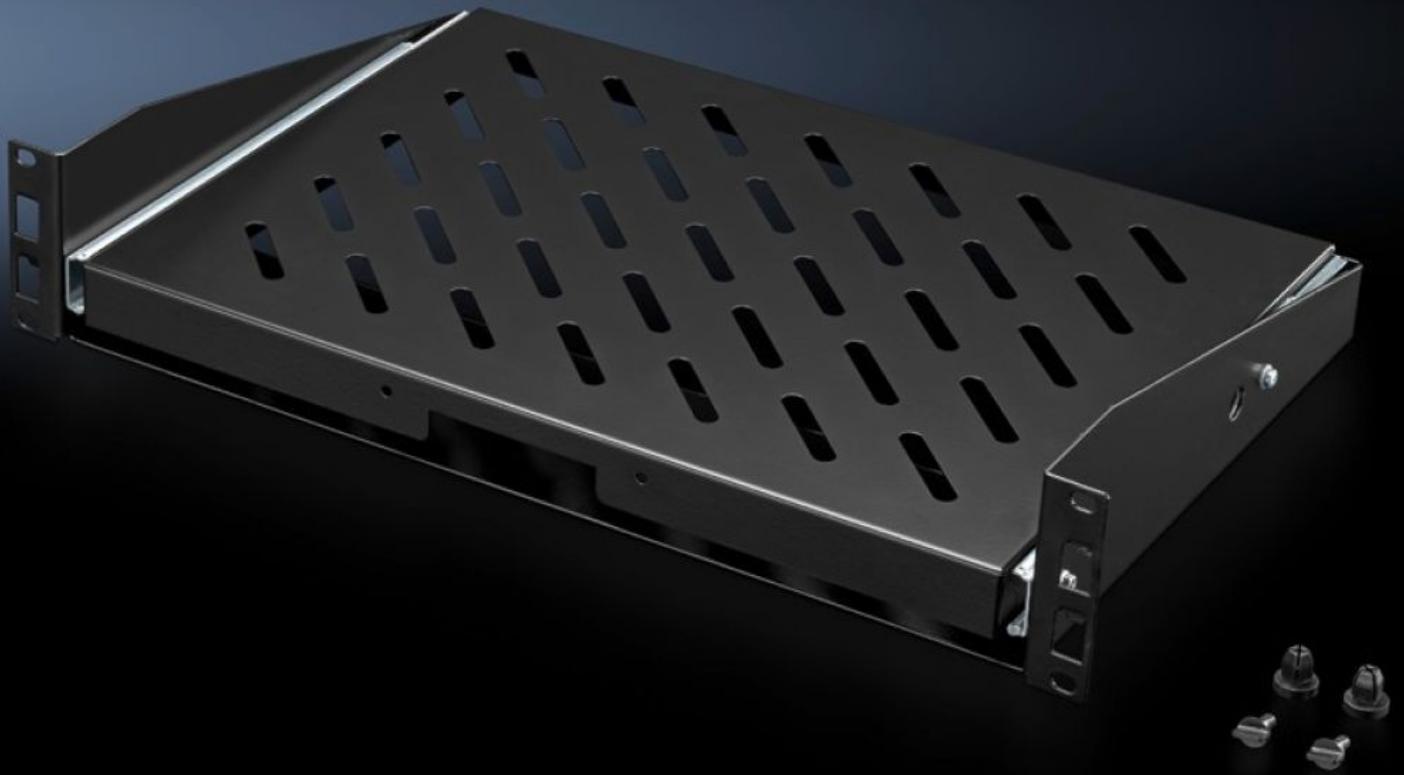

**DK 5501.635**

**Component Shelf, Pull-Out, 2 U**

State: 5/9/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 5501.635 - Component Shelf, Pull-Out, 2 U for a 482.6 mm (19") mounting level

This complete kit contains the pre-configured variant that includes telescopic slides, recessed grip, flange and locking pins.

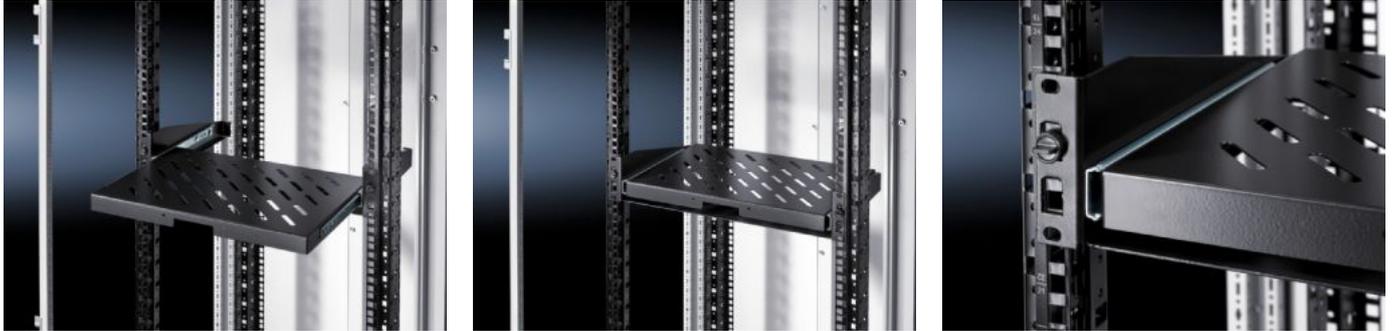

## Features

Model No.	DK 5501.635
Product description	For the simple, front installation of wall-mounted or floor-standing housings with at least one 19" mounting level. This complete kit contains the pre-configured variant that includes telescopic slides, recessed grip, flange and locking pins.
Benefits	Simple, tool-free assembly Full withdrawal Self-locking
Material	Carbon steel
Surface finish	Spray-finished
Color	RAL 9005
Supply includes	Component shelves, preassembled Assembly components
Load capacity static	250 N 56.202 lbf.
Contact surface	Width: 430 mm Depth: 300 mm Width: 16.9 " Depth: 11.8 "

# Features

Packaging unit	1 pc(s).
Net weight	3 kg
Gross weight	3.74 kg
Customs tariff number	73269098
ETIM 9	EC002620
ECLASS 8.0	27189261
Product description	DK Component shelf, for one 482.6 mm (19") mounting level, pull-out, 2 U, Pre-configured variant including telescopic slides,, moulded handle, flange and locking pins