


**Rittal – The System.**

Faster – better – everywhere.

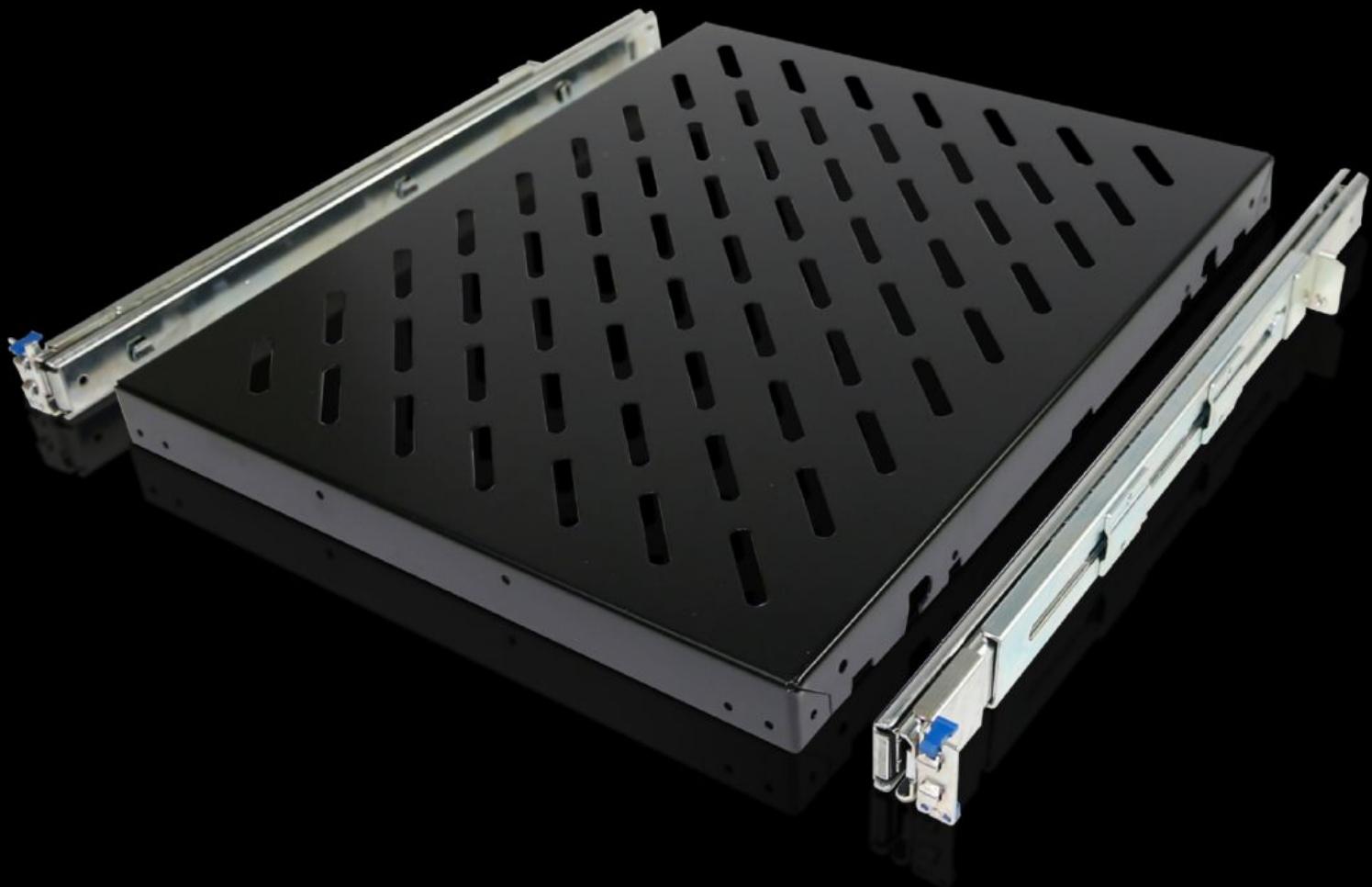

**DK 5501.675**

**Component shelf, pull-out**

State: 2/3/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# DK 5501.675 - Component shelf, pull-out for VX IT, TS IT, TE, TX CableNet

Mounted between two 19" mounting levels.

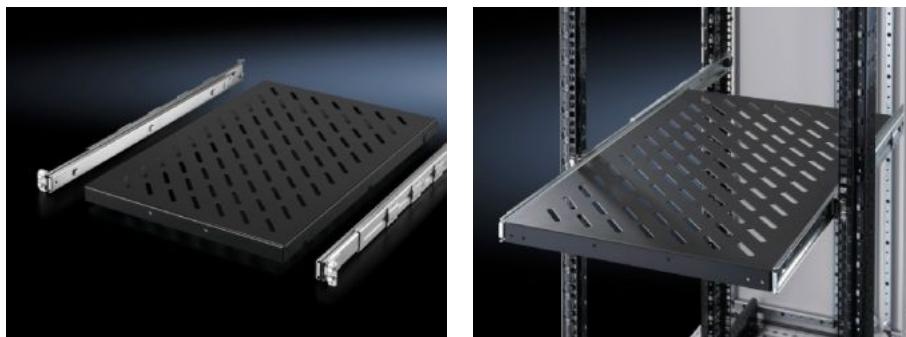

## Features

Model No.	DK 5501.675
Product description	For mounting to 19" profile rails or 19" mounting frames between two 19" mounting levels.
Benefits	Tool-free, time-saving one-person assembly from the front of the enclosure Self-locking Full withdrawal
Applications	Depth-variable to adapt to individual distances between levels
Material	Carbon steel
Surface finish	Base: Spray-finished Telescopic slides/installation kit: zinc-plated
Color	RAL 9005
Supply includes	Component shelf, slotted Telescopic slide with mounting kit Assembly components
Applications	For larger distances between levels, you will need to reduce the preconfigured distance, load capacity 50 kg.
Load capacity	50 kg

# Features

Dimensions	Width: 419 mm Depth: 500 mm Width: 16.5 " Depth: 19.7 "
Suitable for	Enclosure type: VX IT TS IT TE TX CableNet
Distance between levels	400 - 600 mm 15.7 - 23.6 "
Packaging unit	1 pc(s).
Net weight	5.9
Gross weight	6.14
PCF/VE (cradle-to-gate)	23.6 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73269098
EAN	4028177679115
E-Number Sweden	E7239594
ETIM 9	EC002620
ECLASS 8.0	27189261