


Rittal – The System.

Faster – better – everywhere.

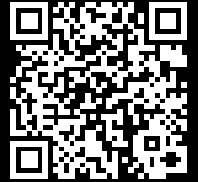

DK 5501.825

Air baffle plates for TS IT 19" profile frames

State: 6/21/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 5501.825 - Air baffle plates for TS IT 19" profile frames

To separate the hot/cold zones within an enclosure with aisle containment or when using an LCP system.



Features

Model No.	DK 5501.825
Product description	With all-round brush strip for partitioning without disruption when busbar systems are installed on the outer mounting level.
Applications	To separate the hot/cold zones within an enclosure with aisle containment or when using an LCP system.
Material	Carbon steel Blanking panel: Plastic, UL 94-HB, halogen-free Brush strip: Plastic, UL 94-HB
Surface finish	Spray-finished
Color	RAL 9005
Supply includes	2 vertical trim panels 2 horizontal trim panels 4 brush strips 4 cellular PU foam pieces Assembly components
Mounting tip	For partitioning, the vertical trim panels with brush strips can be mounted to both the front and rear 19" profile rails. The horizontal trim panels with brush strips can only be mounted on the front 19" profile rails.

Features

Suitable for	Width: 600 mm Height: 2,200 mm Width: 23.6 " Height: 86.6 "
Packaging unit	1 pc(s).
Net weight	4.918 kg
Gross weight	5.177 kg
Customs tariff number	73269098
ETIM 9	EC000331
ECLASS 8.0	27189272
Product description	DK Air baffle plate, WxH: 600x2200 mm, For TS IT 482.6 mm (19") mounting angles