 


Rittal – The System.

Faster – better – everywhere.



DK 5501.915

Air baffle plates for TS IT 19" mounting frames

State: 8/4/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 5501.915 - Air baffle plates for TS IT 19" mounting frames

To separate the hot/cold zones within an enclosure with aisle containment or when using an LCP system.

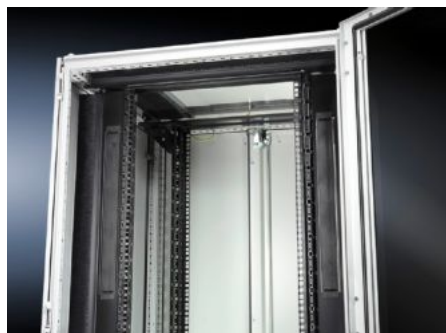

Features

Model No.	DK 5501.915
Product description	With all-round brush strip for partitioning without disruption when rail systems are installed on the outer mounting level.
Applications	To separate the hot/cold zones within an enclosure with aisle containment or when using an LCP system.
Material	Carbon steel Blanking panel: Plastic, UL 94-HB, halogen-free Brush strip: Plastic, UL 94-HB
Surface finish	Spray-finished
Color	RAL 9005
Supply includes	2 vertical trim panels 2 horizontal trim panels 4 brush strips Assembly components 2 blanking panels, 3 U
Mounting tip	For partitioning, the vertical and horizontal trim panels with brush strips can be mounted to both the front and rear 19" mounting frame.

Features

Suitable for	Width: 800 mm Height: 2,000 mm Width: 31.5 “ Height: 78.7 “
Packaging unit	1 pc(s).
Net weight	5.57
Gross weight	6.77
Customs tariff number	73269098
EAN	4028177706934
E-Number Sweden	E7239983
ETIM 9	EC000331
ECLASS 8.0	27189272