


Rittal – The System.

Faster – better – everywhere.

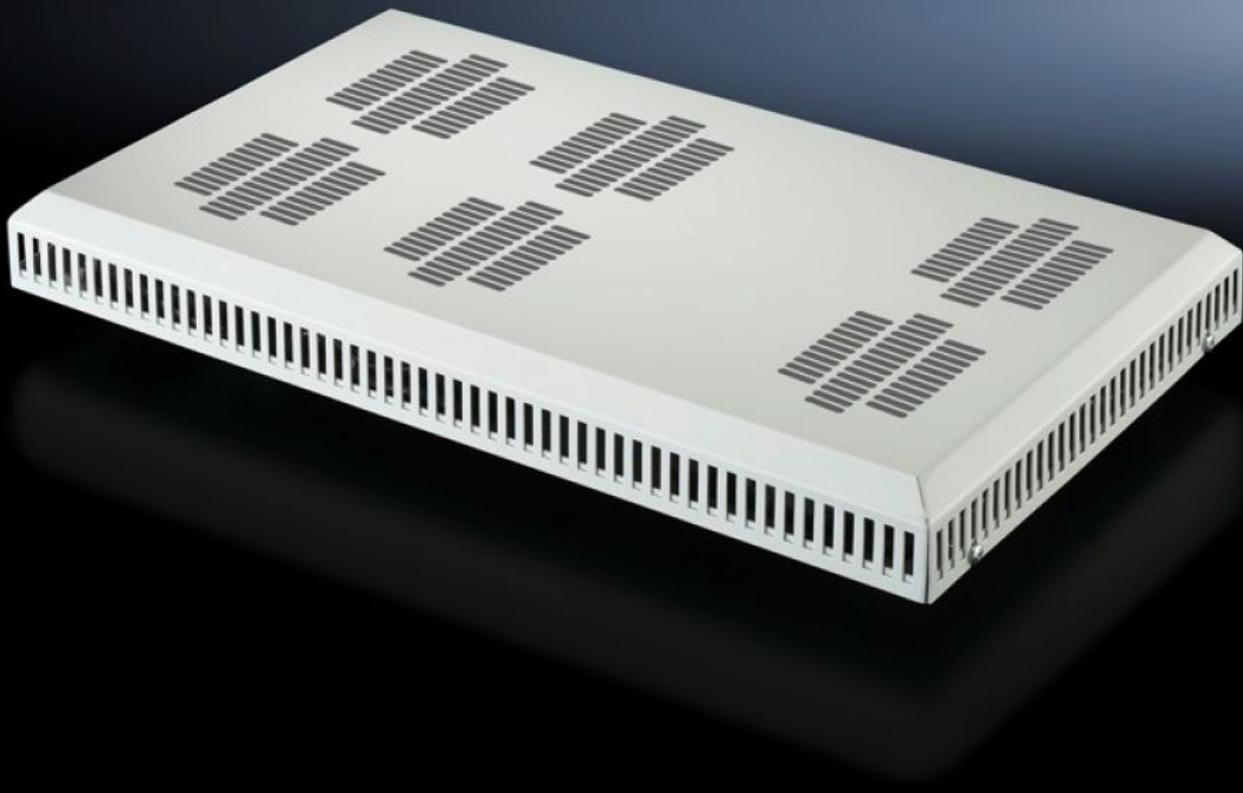

DK 5502.020

Fan tray

State: 5/13/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 5502.020 - Fan tray for VX IT, TS IT, TX CableNet

For active ventilation of the VX IT, TS IT, or TE 8000, depending on the version.



Features

Model No.	DK 5502.020
Product description	For active ventilation. The unit may optionally be extended with additional fans.
Applications	For use in the cut-out integrated into the roof plate
Color	RAL 7035
Supply includes	1 fan unit 2 fans 1 thermostat Connection cable, open-end Assembly components
Air throughput per fan (unimpeded air flow)	160/180 94.2/105.9
Rated operating voltage	230 V, 1~, 50 Hz/60 Hz
Dimensions	Width: 340 mm Height: 54 mm Depth: 550 mm Width: 13.4 " Height: 2.13 " Depth: 21.7 "
Air throughput of fans (unimpeded air flow)	1514

Features

Installation options	In the VX IT with W x D (mm): 800 x 800/800 x 1000/800 x 1200 In the TS IT with W x D (mm): 800 x 800/800 x 1000/800 x 1200 In the TE 8000 with W x D (mm): 600 x 600/600 x 800/600 x 1,000/800 x 600/800 x 800/800 x 1,000
Note	The specified sound level relates to the first fan Connection via distributor box or country-specific connector
Sound pressure level per fan	37 dB(A)
Suitable for	Enclosure type: VX IT TS IT
Operating temperature range	5 °C...55 °C 41 °F...131 °F
Packaging unit	1 pc(s).
Net weight	4.3 kg
Gross weight	4.38 kg
Customs tariff number	84149000
ECLASS 8.0	27189272
Product description	DK fan mounting plate, for use in roof plate, incl. 2 fans, expandable to max. 6 fans, WHD: 340x59x550 mm

Approvals

Explanations	Declaration of conformity UK
--------------	------------------------------