


# Rittal – The System.

Faster – better – everywhere.

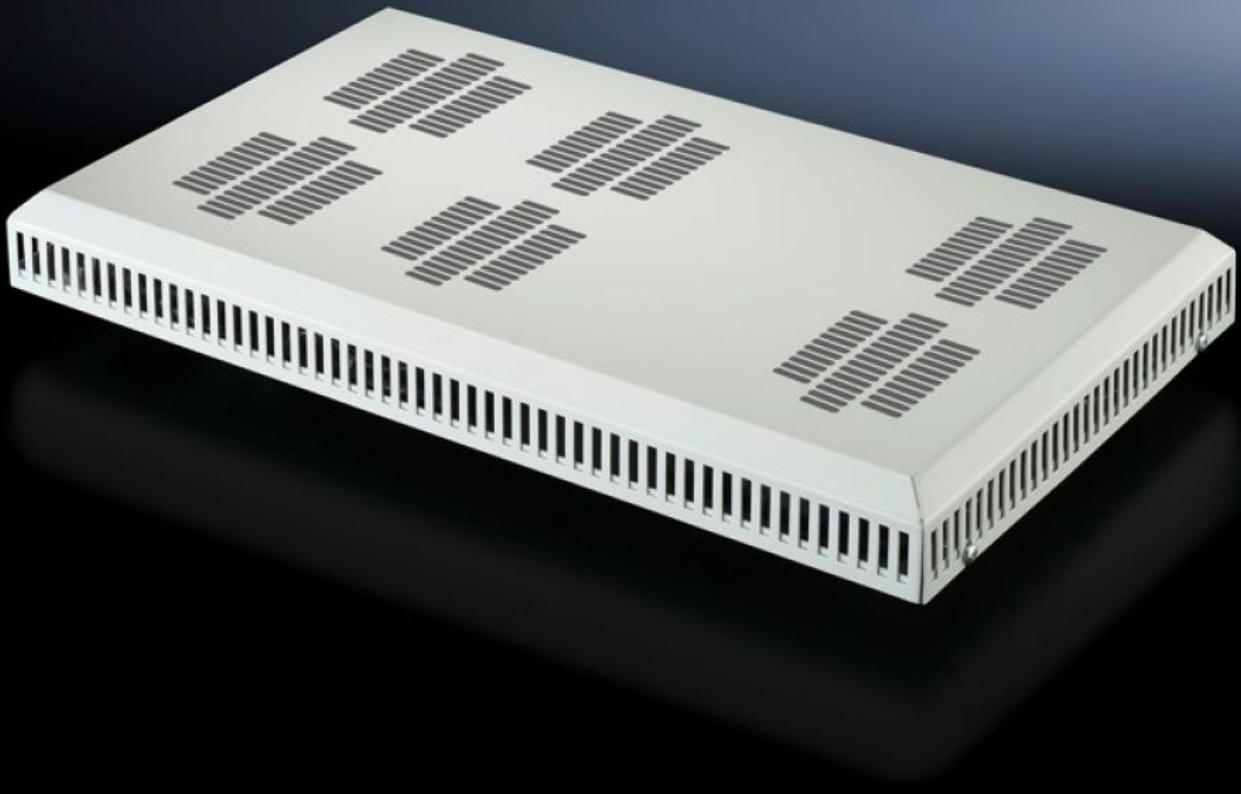

## DK 5502.020

## Fan tray

State: 4/7/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 5502.020 - Fan tray for VX IT, TS IT, TX CableNet

For active ventilation of the VX IT, TS IT, or TE 8000, depending on the version.



## Features

Model No.	DK 5502.020
Product description	For active ventilation. The unit may optionally be extended with additional fans.
Applications	For use in the cut-out integrated into the roof plate
Color	RAL 7035
Supply includes	1 fan unit 2 fans 1 thermostat Connection cable, open-end Assembly components
Air throughput per fan (unimpeded air flow)	160/180 94.2/105.9
Rated operating voltage	230 V, 1~, 50 Hz/60 Hz
Dimensions	Width: 340 mm Height: 54 mm Depth: 550 mm Width: 13.4 " Height: 2.13 " Depth: 21.7 "
Air throughput of fans (unimpeded air flow)	1514

# Features

Installation options	In the VX IT with W x D (mm): 800 x 800/800 x 1000/800 x 1200 In the TS IT with W x D (mm): 800 x 800/800 x 1000/800 x 1200 In the TE 8000 with W x D (mm): 600 x 600/600 x 800/600 x 1,000/800 x 600/800 x 800/800 x 1,000
Note	The specified sound level relates to the first fan Connection via distributor box or country-specific connector
Sound pressure level per fan	37 dB(A)
Suitable for	Enclosure type: VX IT TS IT
Operating temperature range	5 °C...55 °C 41 °F...131 °F
Packaging unit	1 pc(s).
Net weight	4.3 kg
Gross weight	4.38 kg
Customs tariff number	84149000
ECLASS 8.0	27189272
Product description	DK fan mounting plate, for use in roof plate, incl. 2 fans, expandable to max. 6 fans, WHD: 340x59x550 mm

# Approvals

Explanations	Declaration of conformity UK
--------------	------------------------------