

**Rittal – The System.**

Faster – better – everywhere.



**CP 6206.480**

**Connection console VESA 75/100**

State: 6/3/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# CP 6206.480 - Connection console VESA 75/100

For rear connection of flat command panels, standard TFTs and industrial PCs with VESA 75/100 connection. May be connected to Rittal CP 40 and CP 60 support arm systems, and also to CP 120 by using a Ø 130 mm to rectangular 120 x 65 mm support arm connection adaptor.

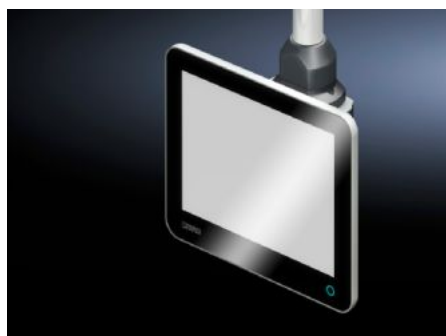

## Features

Model No.	CP 6206.480
Version	Connection to Rittal support arm systems
Product description	For rear connection of flat operating housings, standard TFTs and industrial PCs with VESA 75/100 connection.
Benefits	Fast, simple one-person assembly using machined keyholes More space for installation and servicing Cables may be routed to devices outside and below the console Removable cover for easy cable routing and access to interior device connections Integral cable clamping facilities Cover and captive screws
Material	Die-cast zinc
Color	Connection console: RAL 7035 Cover: RAL 7024
Supply includes	Seal and assembly components Cable ties for cable clamping
Rifid y/n	Yes
Note	Depending on the application, an attachment, coupling or adapter are required
Load capacity	800 N

# Features

---

Packaging unit	1 pc(s).
Net weight	2.5 kg
Gross weight	2.775 kg
Customs tariff number	73269098
ETIM 9	EC002622
ECLASS 8.0	27189263
Product description	CP Connection console VESA 75/100

# Approvals

---

Explanations	Manufacturer's declaration
--------------	----------------------------