

# Rittal – The System.

Faster – better – everywhere.



## DK 7030.060 CMC III power pack

State: 6/7/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7030.060 - CMC III power pack For PU, PU Compact, LED light strip, Door Control Module

CMC III power pack for use in various voltage ranges.

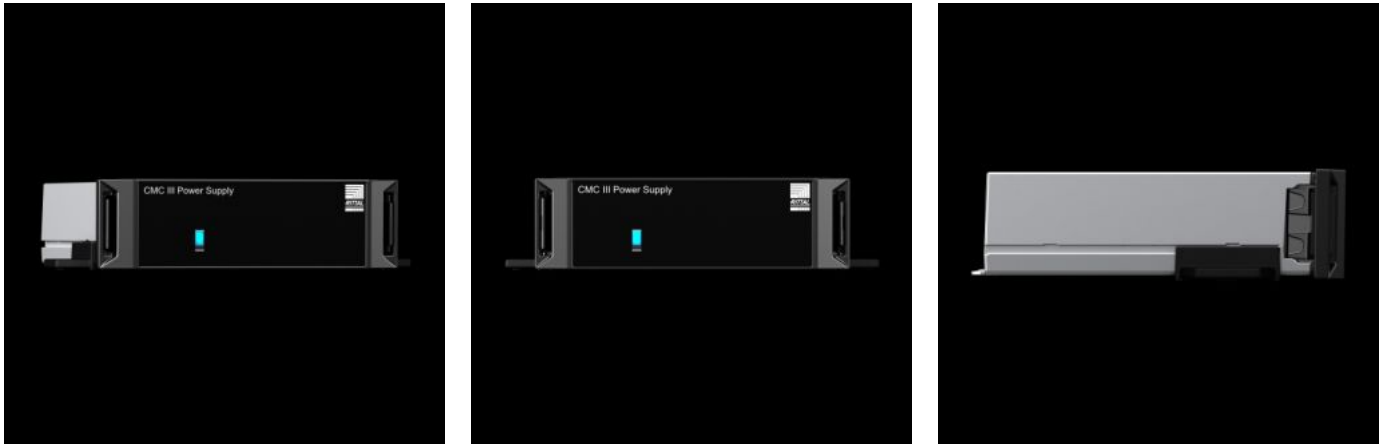

## Features

Model No.	DK 7030.060
Product description	The power pack is specifically adapted to the CMC III design and can be placed in a mounting unit. As well as a special connector for the CMC III Processing Unit/Compact, there are also two terminals as 24 V outputs.
Material	Plastic
Surface finish	Front: Smooth Housing: Textured
Color	Front: RAL 9005 Housing: RAL 7035
Supply includes	Connection cable 24 V (DC) Incl. assembly parts for mounting on surfaces
Length of connection cable	600 mm 23.6 "
Input connection	Non-heating apparatus connector C14
Output current (max.)	2.5 A

# Features

---

Dimensions	Width: 138 mm Height: 40 mm Depth: 132 mm Width: 5.43 " Height: 1.57 " Depth: 5.2 "
Operating temperature range	0 °C...40 °C 32 °F...104 °F
Output voltage	Output voltage: 24 V DC
Ambient humidity (non-condensing)	5...95 %
Packaging unit	1 pc(s).
Net weight	0.65 kg
Gross weight	0.652 kg
Customs tariff number	85043121
ETIM 9	EC002627
ECLASS 8.0	27189253
Product description	DK CMC III Power pack, For power supply of the CMC III Processing Units, Input: C14 100-230 V, 50/60 Hz, Output: 24 V DC, 2 A

---

# Approvals

---

Approvals	UR + C-UR (recognized)
Explanations	Manufacturer's declaration Declaration of conformity

---