

Rittal – The System.

Faster – better – everywhere.



DK 7030.060 CMC III power pack

State: 6/10/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7030.060 - CMC III power pack For PU, PU Compact, LED light strip, Door Control Module

CMC III power pack for use in various voltage ranges.

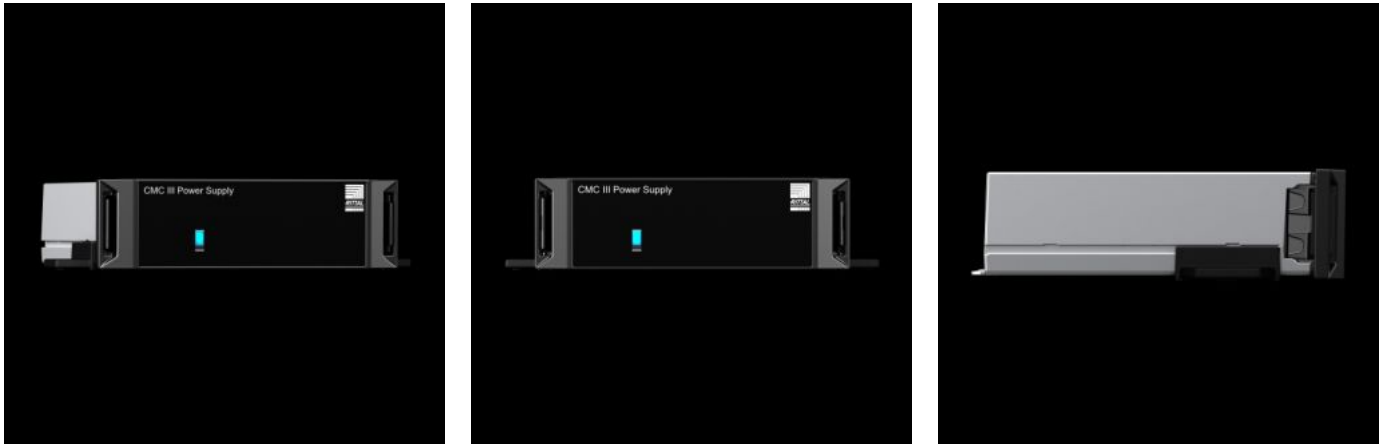

Features

Model No.	DK 7030.060
Product description	The power pack is specifically adapted to the CMC III design and can be placed in a mounting unit. As well as a special connector for the CMC III Processing Unit/Compact, there are also two terminals as 24 V outputs.
Material	Plastic
Surface finish	Front: Smooth Housing: Textured
Color	Front: RAL 9005 Housing: RAL 7035
Supply includes	Connection cable 24 V (DC) Incl. assembly parts for mounting on surfaces
Length of connection cable	600 mm 23.6 "
Input connection	Non-heating apparatus connector C14
Output current (max.)	2.5 A

Features

Dimensions	Width: 138 mm Height: 40 mm Depth: 132 mm Width: 5.43 " Height: 1.57 " Depth: 5.2 "
Operating temperature range	0 °C...40 °C 32 °F...104 °F
Output voltage	Output voltage: 24 V DC
Ambient humidity (non-condensing)	5...95 %
Packaging unit	1 pc(s).
Net weight	0.65 kg
Gross weight	0.652 kg
Customs tariff number	85043121
ETIM 9	EC002627
ECLASS 8.0	27189253
Product description	DK CMC III Power pack, For power supply of the CMC III Processing Units, Input: C14 100-230 V, 50/60 Hz, Output: 24 V DC, 2 A

Approvals

Approvals	IEC CB UR + C-UR (recognized)
Explanations	Manufacturer's declaration Declaration of conformity
