

**Rittal – The System.**

Faster – better – everywhere.



**DK 7119.140**

# Component Shelf 1 U, Static Installation

State: 4/27/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7119.140 - Component Shelf 1 U, Static Installation 482.6 mm (19") system punchings

482.6 mm (19")/535 mm (metric), support surface for small active components such as modems or mini-hubs in 19" or metric levels: 10 kg.

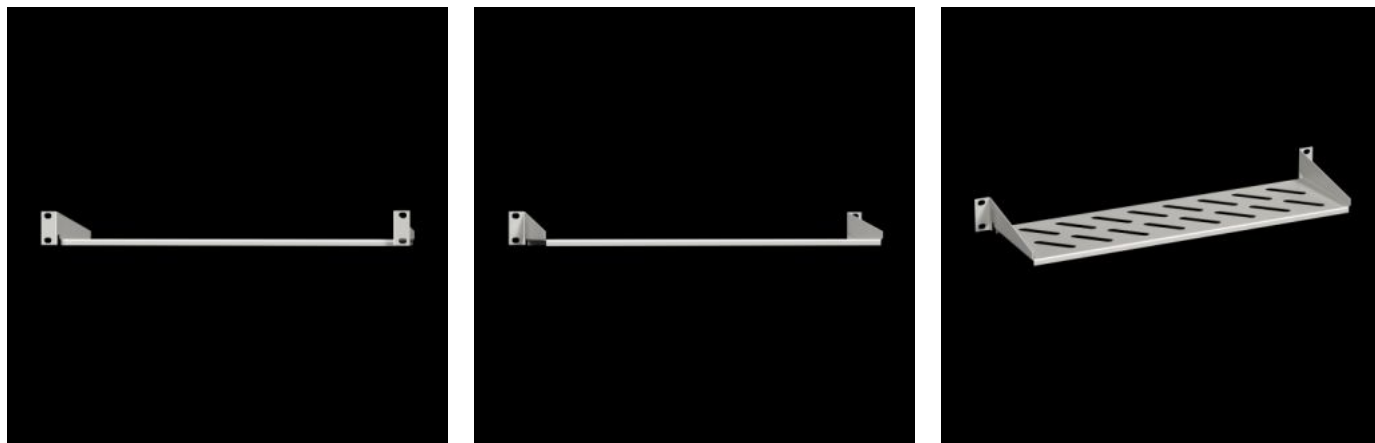

## Features

Model No.	DK 7119.140
Version	482.6 mm (19") version
Product description	The ideal support surface for small active components such as modems or mini-hubs.
Material	Carbon steel
Color	RAL 7035
Load capacity	10 kg surface load, static
Note	Not suitable for combination with telescopic slides. Free installation height inside the U approx. 35 mm
Dimensions	Width: 482.6 mm Depth: 140 mm Width: 19 " Depth: 5.51 "
Packaging unit	1 pc(s).
Net weight	0.781 kg
Gross weight	0.881 kg

# Features

PCF/VE (cradle-to-gate)	3.2 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	94039910
ETIM 9	EC002620
ECLASS 8.0	27189261
Product description	DK Component shelf, WHD: 482,6x1 Ux140 mm, 10 kg, static, distance between levels:, static installation, For 482.6 mm (19") system punchings, RAL 7035