

Rittal – The System.

Faster – better – everywhere.



DK 7296.000

Second Mounting Level

State: 6/19/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7296.000 - Second Mounting Level for Data Rack

To accommodate 482.6 mm (19") network components or to mount component shelves and slide rails.

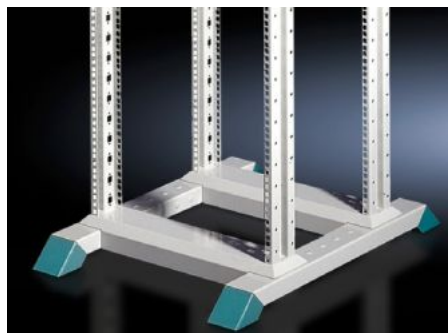

Features

| | |
|-------------------------|---|
| Model No. | DK 7296.000 |
| Product description | To accommodate 482.6 mm (19") network components or to mount component shelves and slide rails. 482.6 mm (19") profiles holes at the front, hole center-to-center spacing 465 mm, rear 470 mm, designed for the attachment of patch panels and cable routing rails. The mounting level can be positioned in the 50 mm hole pattern. Minimum clearance between levels 150 mm, maximum clearance between levels 350 mm. |
| Material | Carbon steel, 2 mm |
| Surface finish | Spray-finished |
| Color | Profile frame: RAL 7035 Trim Panel: RAL 5018 |
| Supply includes | Torsionally rigid profile frame with 482.6 mm (19") holes Mounting Accessories |
| Installation dimensions | Installation depth for components: 482.6 mm Installation width for components: 19" Installation depth for components: 19" Installation width for components: 19" |
| Height units | 31 U |
| Packaging unit | 1 pc(s). |
| Net weight | 11.101 kg |

Features

| | |
|-------------------------------------|--|
| Gross weight | 11.685 kg |
| PCF/VE (cradle-to-gate) | 44.5 kg CO2 eq (Cat B) |
| Information regarding the PCF class | Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared |
| Customs tariff number | 94039910 |
| ETIM 9 | EC002620 |
| ECLASS 8.0 | 27189261 |
| Product description | DK Second pair of mounting angles, 31 U, 482.6 mm (19"), For Data Rack |