


**Rittal – The System.**

Faster – better – everywhere.

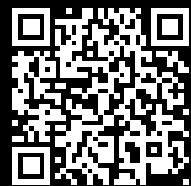

**DK 7480.300**

**Energy-Box, 482.6 mm (19")**

State: 2/1/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7480.300 - Energy-Box, 482.6 mm (19") Pull-out

Designed to accommodate both DC and AC components, pull-out component facia affords optimum access to the wiring compartment from above and below.

## Features

Model No.	DK 7480.300
Product description	Depth-variable top hat rail for "snap-in" fastening of installed equipment to DIN 43 880 sizes 1 – 3 (e.g. to accommodate flush-type outlets, circuit breakers, etc. or entire installation groups). Rear cable clamping. Two power distribution rails with connection terminals on insulated base. Plastic cover including reserve panel cover. To accommodate a maximum of 22 TE (22 x 18 mm = 396 mm). Housing height: 3 U. Housing depth: 223 mm. Maximum dimensions when pulled out: 220 mm. Connection terminals: 4 35 mm <sup>2</sup> terminals, 18 16 mm <sup>2</sup> terminals (per rail).
Color	RAL 7035
Supply includes	Energy box with plastic blanking covers. Terminal 18 connection clamps, 16 mm <sup>2</sup> 4 connection clamps, 35 mm <sup>2</sup> Strain relief Identification strips Brush strip
Max. pitch units @ 18 mm	22
Dimensions	Width: 482.6 mm Depth: 220 mm Width: 19 " Depth: 8.66 "
Height units	3 U
Packaging unit	1 pc(s).
Net weight	6.1
Gross weight	6.14
Customs tariff number	94032080

# Features

---

EAN	4028177247529
E-Number Sweden	E7239509
ETIM 9	EC002006
ECLASS 8.0	27189268

---