
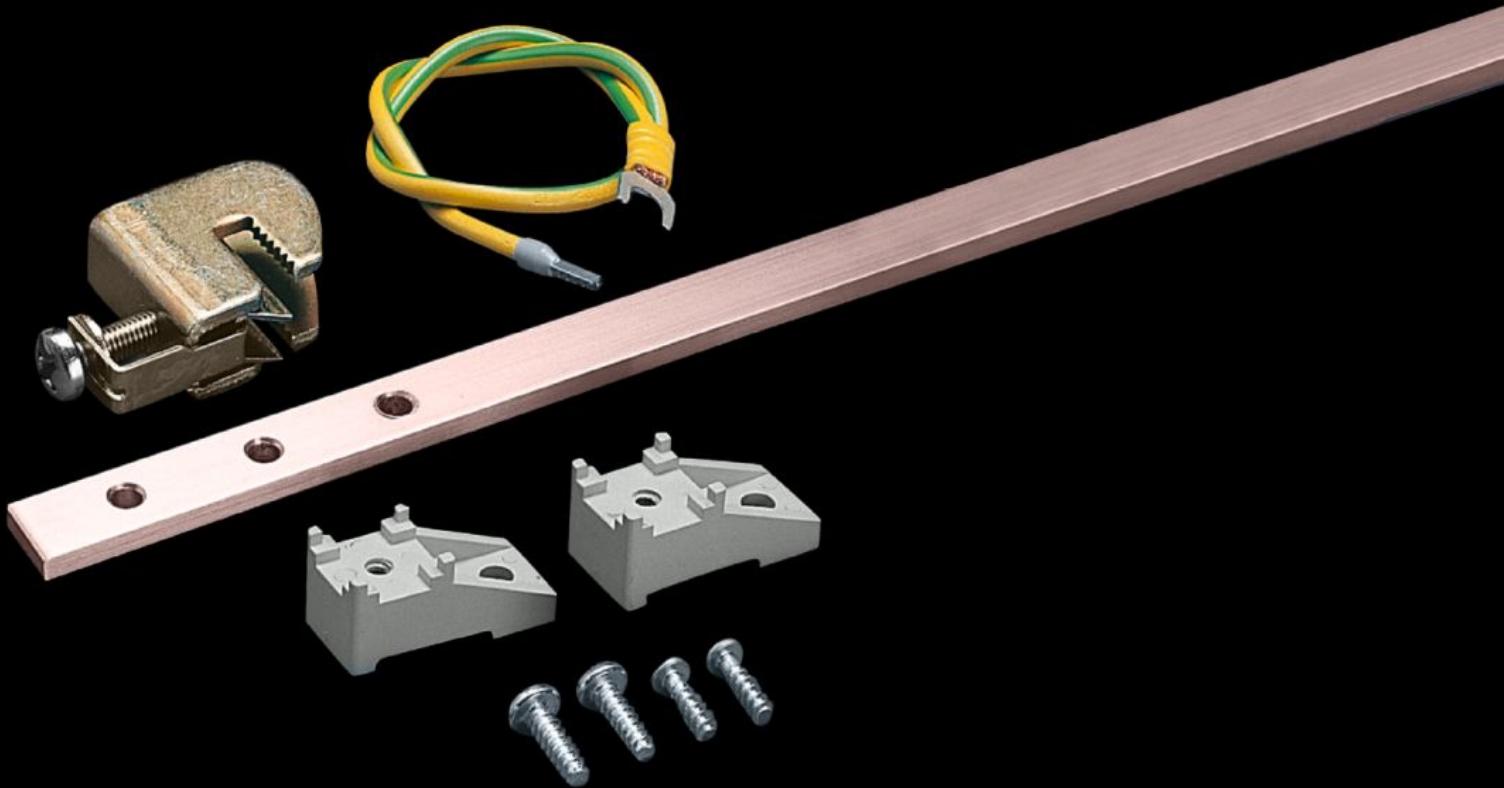


Rittal – The System.

Faster – better – everywhere.

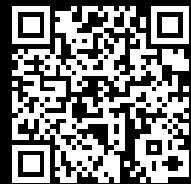

DK 7541.000

Ground rail, vertical

State: 1/30/2026 (Source: ittal.com/us-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

DK 7541.000 - Ground rail, vertical for VX, VX IT

The supplied ground conductors facilitate star grounding of cable clamp straps on patch panels, ground terminals are fully adjustable, rail current carrying capacity approx. 200 A.

Features

Model No.	DK 7541.000
Product description	Easy to mount on 25 mm DIN hole pattern on distributor or on 482.6 mm (19") punched rails. The supplied ground conductors facilitate star grounding of cable clamp straps on patch panels. The ground terminals are fully adjustable. Rail current carrying capacity approx. 200 A.
Supply includes	Ground rail made from E-Cu 57 to DIN EN 12 163, DIN EN 13 601, 15 x 5 mm null 15 grounding leads 6 mm ² , L = 500 mm Assembly components
Dimensions	Length: 545 mm Length: 21.5 "
Suitable for	Enclosure type: VX VX IT TS Height: 800 mm Enclosure type: VX VX IT TS Height: 31.5 "
Packaging unit	1 pc(s).
Net weight	1.272
Gross weight	1.472
Customs tariff number	74198090
EAN	4028177131798
ETIM 9	EC000329

Features

ECLASS 8.0

27400605