


Rittal – The System.

Faster – better – everywhere.

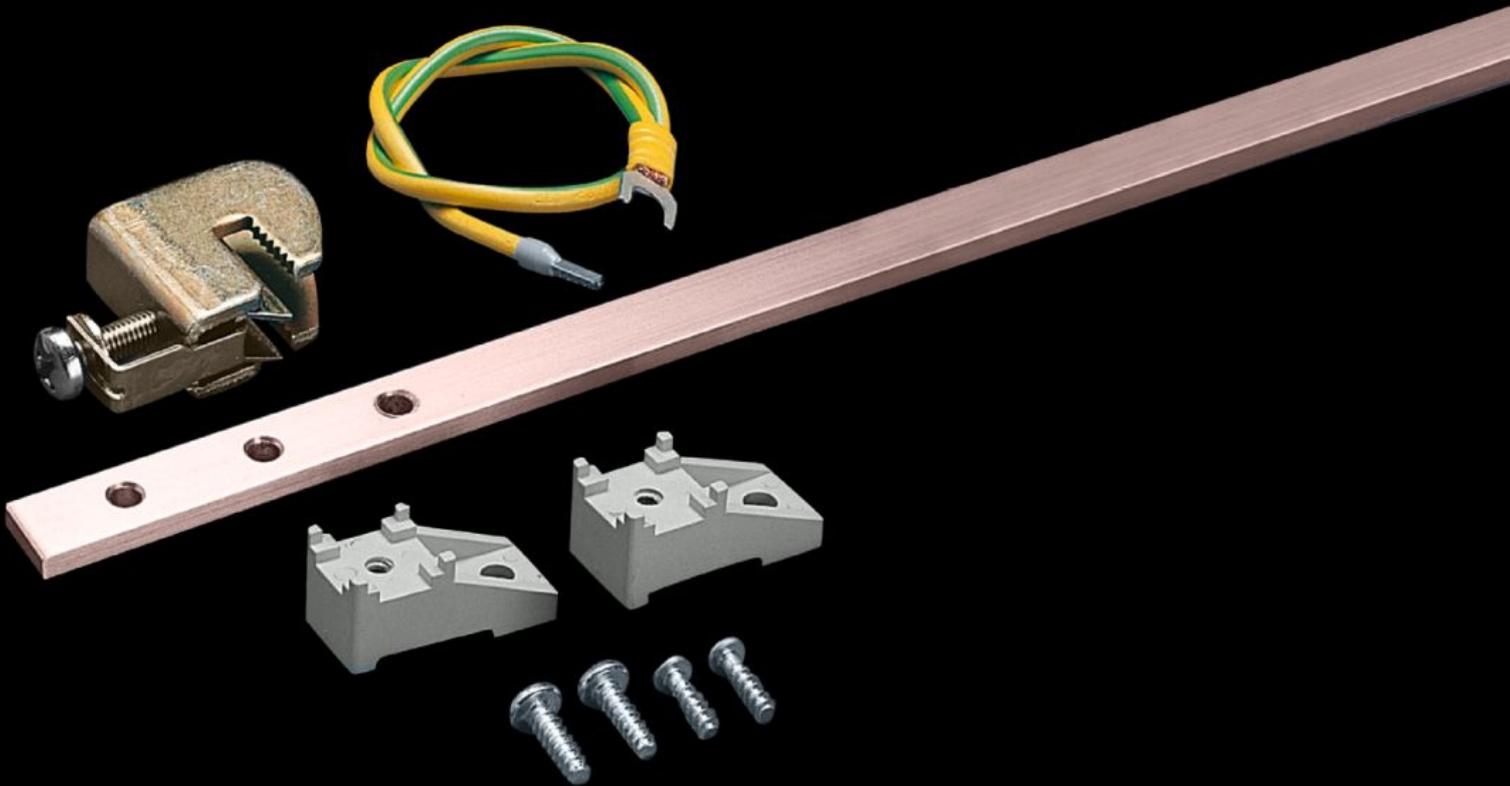

DK 7547.000 Ground rail, vertical

State: 5/8/2026 (Source: rittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7547.000 - Ground rail, vertical for VX, VX IT

The supplied ground conductors facilitate star grounding of cable clamp straps on patch panels, ground terminals are fully adjustable, rail current carrying capacity approx. 200 A.

Features

| | |
|-----------------------|---|
| Model No. | DK 7547.000 |
| Product description | Easy to mount on 25 mm DIN hole pattern on distributor or on 482.6 mm (19") punched rails. The supplied ground conductors facilitate star grounding of cable clamp straps on patch panels. The ground terminals are fully adjustable. Rail current carrying capacity approx. 200 A. |
| Supply includes | Ground rail made from E-Cu 57 to DIN EN 12 163, DIN EN 13 601, 15 x 5 mm null 15 grounding leads 6 mm ² , L = 500 mm Assembly components |
| Dimensions | Length: 1,745 mm Length: 68.7 " |
| Suitable for | Enclosure type: VX VX IT TS Height: 2,000 mm Enclosure type: VX VX IT TS Height: 78.7 " |
| Packaging unit | 1 pc(s). |
| Net weight | 2.4 kg |
| Gross weight | 2.62 kg |
| Customs tariff number | 74198090 |
| ETIM 9 | EC000329 |
| ECLASS 8.0 | 27400605 |

Features

Product description

DK earth rail, vertical, L: 1745 mm, grounding lead: 15x 6 mm², L: 500 mm, conductor terminals: 16x 2.5-16 mm²