


**Rittal – The System.**

Faster – better – everywhere.

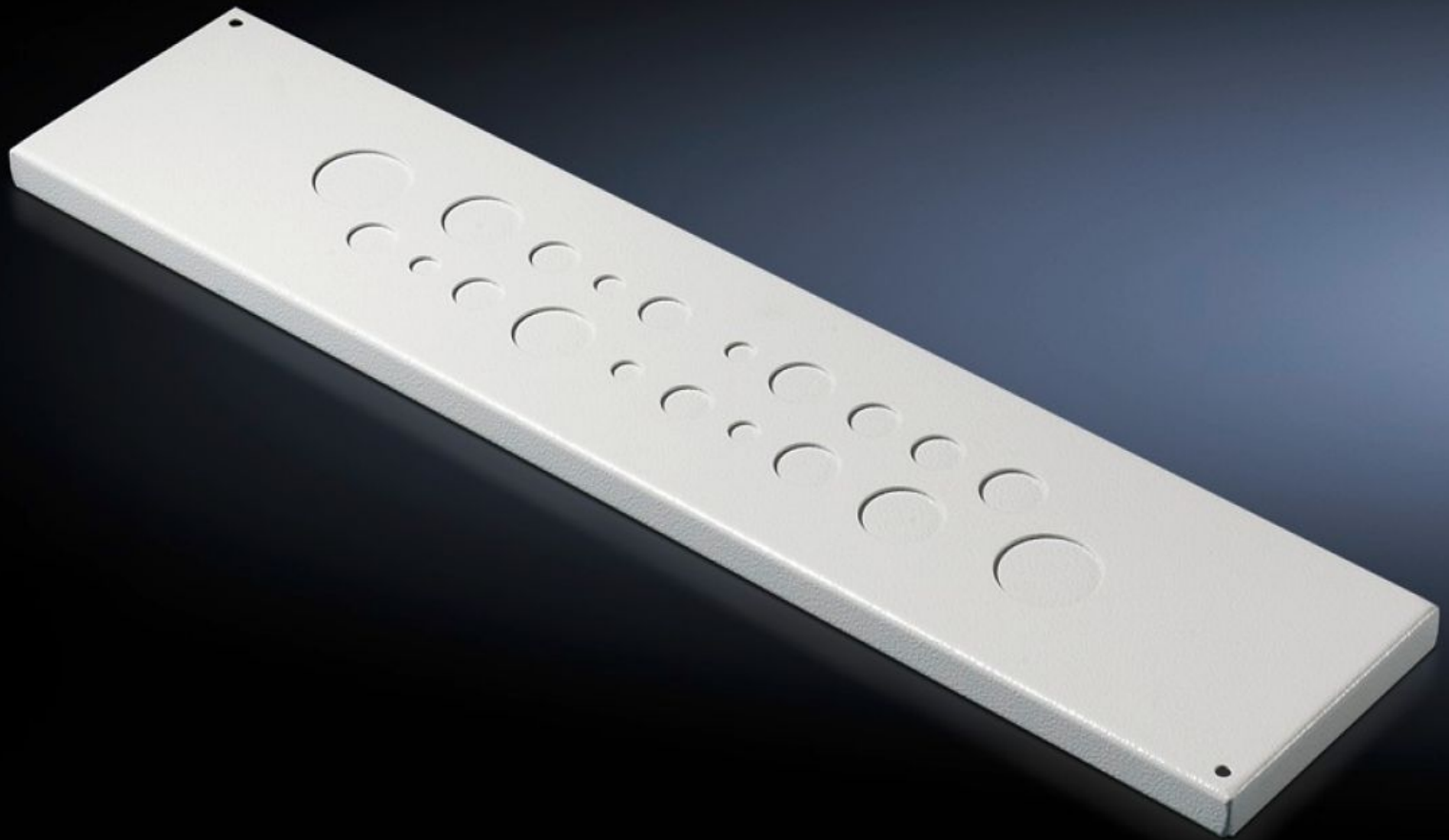

**EL 7705.235**

**Gland plate for metric cable glands**

State: 4/17/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# EL 7705.235 - Gland plate for metric cable glands for EL

Folded flange plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands.

## Features

Model No.	EL 7705.235
Product description	Folded flange plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands M12, M20, M25, M32, M40.
Material	Carbon steel, 1.5 mm
Color	RAL 7035
No. of metric knockouts	4 x M12 8 x M20 6 x M25 1 x M32 1 x M40
Dimensions	Width: 599 mm Depth: 133.5 mm Width: 23.6 " Depth: 5.26 "
Protection category IP to EN 60529	IP 55
Packaging unit	1 pc(s).
Net weight	1.55 kg
Gross weight	1.64 kg
PCF/VE (cradle-to-gate)	6.2 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73079100
ETIM 9	EC000211
ECLASS 8.0	27142421

# Features

---

Product description

EL Gland plate for metric cable glands, WxD: 599x133,5 mm, For EL