


Rittal – The System.

Faster – better – everywhere.

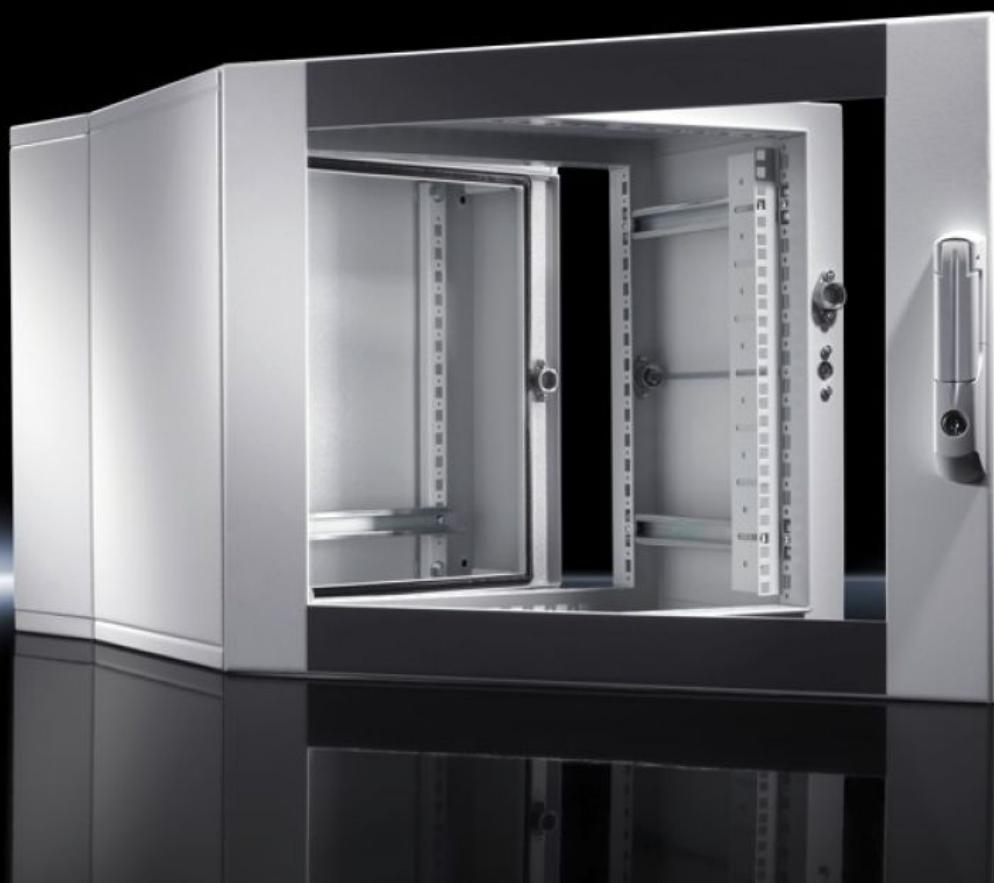

DK 7709.135

Wall-mounted enclosures EL, 3-part

State: 2/5/2026 (Source: rittal.com/us-en)



FRIEDHELM LOH GROUP

DK 7709.135 - Wall-mounted enclosures EL, 3-part with punched rails and profile rails, depth-variable

Wall-mounted housing 3-part, pre-configured with: Solid flange plate, top and bottom, punched rails, C rails, wall mounting bracket. Protection category IP 55.

Features

| | |
|---------------------|---|
| Model No. | DK 7709.135 |
| Version | Wall-mounted housing IT with punched rails and profile rails, depth-variable |
| Product description | Wall-mounted enclosure with hinged door provides optimum accessibility. |
| Material | Wall and hinged part: Carbon steel, 1.5 mm Viewing window: Single-pane safety glass, 3 mm |
| Surface finish | Powder-coated |
| General color | RAL 7035 |
| Color | Wall and hinged part: RAL 7035 Viewing door: RAL 7035/7015 (slate gray) |
| Supply includes | Wall section closed at top and bottom with flange (gland) plate, two vertical mounting rails and horizontal C-profile rails for cable clamping. Hinged part with 25 mm pitch pattern in the front and rear frame, two 482.6 mm (19") profile angles at the front, fully depth adjustable 4 wall mounting brackets 10 mm Designer viewing door 1 enclosure key double bit no. 5 Mini-comfort handle for lock inserts Security lock 3524 E |
| Height units | 9 U |

Features

| | |
|--|--|
| Dimensions | Width: 600 mm Height: 478 mm Depth: 473 mm Width: 23.6 " Height: 18.8 " Depth: 18.6 " |
| Installation depth | 420 mm 16.5 " |
| Clearances | Clearance width: 502 mm Clearance height: 415 mm Clearance width: 19.8 " Clearance height: 16.3 " |
| Depth hinged part | 316 mm 12.4 " |
| Depth of wall section | 135 mm 5.31 " |
| IK code | IK08 |
| Load capacity of hinged part (static) | 450 N 101.164 lbf. |
| Base material | Carbon steel |
| Protection category IP to EN 60 529 | IP 55 |
| Packaging unit | 1 pc(s). |
| Net weight | 29.45 |
| Gross weight | 31 |
| Customs tariff number | 94032080 |
| EAN | 4028177324183 |
| ETIM 9 | EC000261 |
| ECLASS 8.0 | 27142408 |

Approvals

Approvals

UL + C-UL (listed)