


Rittal – The System.

Faster – better – everywhere.

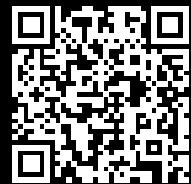

DK 7824.120

Side panel, lockable

State: 2/1/2026 (Source: [ittal.com/us-en](https://www.ittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7824.120 - Side panel, lockable for TS, TS IT

Side panel, lockable, sheet steel, for TS.



Features

Model No.	DK 7824.120
Product description	Locates easily into place at the top. Locked with security lock no. 3524 E. Grounding bolts with contact lug.
Material	Carbon steel
Surface finish	Spray-finished
Color	RAL 7035
Supply includes	2 side panels each with 4 security locks no. 3524 E
Suitable for	Enclosure type: TS TS IT Height: 1,200 mm Depth: 1,000 mm Enclosure type: TS TS IT Height: 47.2 " Depth: 39.4 "
Base material	Carbon steel
Packaging unit	2 pc(s).
Net weight	28.6
Gross weight	29.8
Customs tariff number	94039910

Features

EAN	4028177330672
E-Number Sweden	E7239565
ETIM 9	EC002524
ECLASS 8.0	27182101
