


# Rittal – The System.

Faster – better – everywhere.

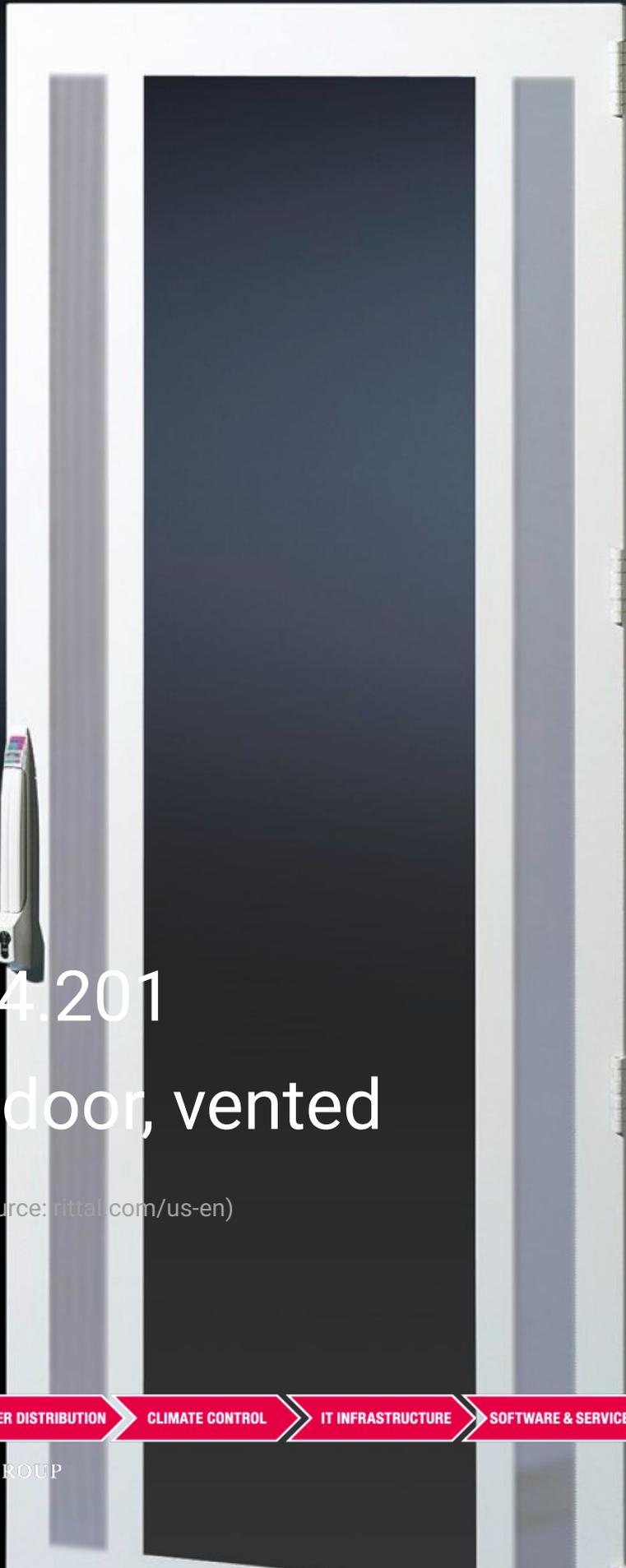

## DK 7824.201 Glazed door, vented

State: 2/28/2026 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7824.201 - Glazed door, vented for TS, TS IT, VX SE

To replace existing doors. With 180° hinges and swivel handle with security lock No. 3524 E.

## Features

Model No.	DK 7824.201
Product description	Surface perforated on both sides with air inlet openings > 78% for optimum air throughput.
Material	Door: Carbon steel Viewing window: Single-pane safety glass, 3 mm
Surface finish	Powder-coated
Color	RAL 7035
Supply includes	Glazed door, vented Comfort handle for semi-cylinders with security lock 3524 E 180° hinges (4 pcs) Assembly components
Mounting tip	For TS bayed enclosure suites with carbon steel doors, only the 180° hinge 7824.520 can be used.
Suitable for	Enclosure type: TS TS IT SE Width: 600 mm Height: 2,000 mm Enclosure type: TS TS IT SE Width: 23.6 " Height: 78.7 "
Packaging unit	1 pc(s).
Net weight	19.38 kg
Gross weight	20.4 kg
Customs tariff number	94039910
ETIM 9	EC000747

# Features

---

ECLASS 8.0

27182204

---

Product description

DK-TS Glazed door, WxH: 600x2000 mm, Vented