


**Rittal – The System.**

Faster – better – everywhere.

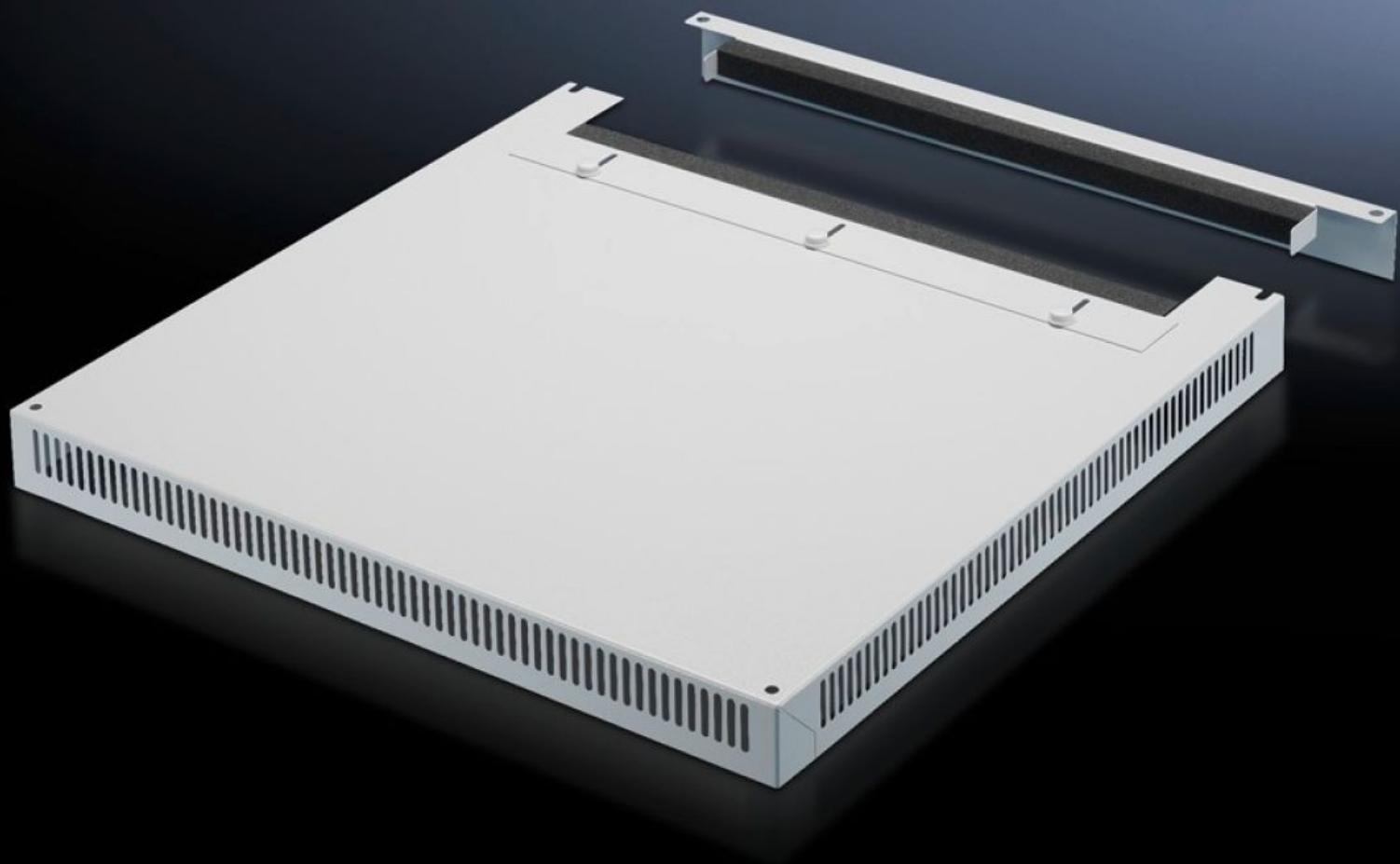

**DK 7826.669**

**Roof Plate, Vented**

State: 2/14/2026 (Source: [ittal.com/us-en](http://ittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7826.669 - Roof Plate, Vented for TS, TS IT

To replace the standard roof, with and without cable entry.

## Features

Model No.	DK 7826.669
Version	Two-piece with cable entry
Product description	To replace standard roof. 72 mm high roof plate, all-round vent slots, clamping profile for cable entry. The two-piece design with cable entry allows for easy retro-fitting.
Material	Carbon steel
Color	RAL 7035
Suitable for	Enclosure type: TS TS IT Width: 600 mm Depth: 600 mm Enclosure type: TS TS IT Width: 23.6 " Depth: 23.6 "
Packaging unit	1 pc(s).
Net weight	6.878
Gross weight	7.24
Customs tariff number	73269098
EAN	4028177390201
ETIM 9	EC000744
ECLASS 8.0	27182405