


**Rittal – The System.**

Faster – better – everywhere.

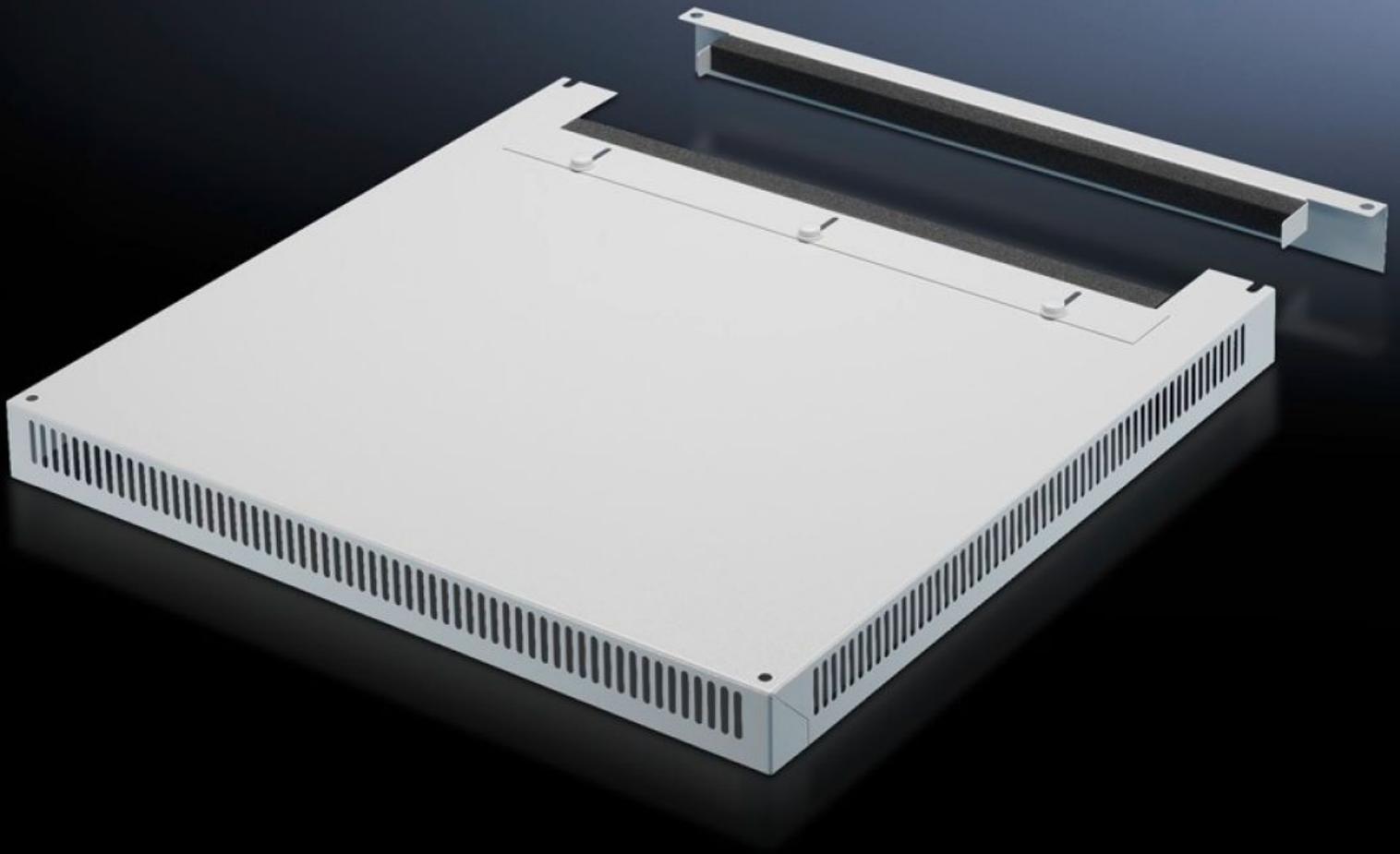

# DK 7826.809

## Roof Plate, Vented

State: 2/28/2026 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7826.809 - Roof Plate, Vented for TS, TS IT

To replace the standard roof, with and without cable entry.

## Features

Model No.	DK 7826.809
Version	Two-piece with cable entry
Product description	To replace standard roof. 72 mm high roof plate, all-round vent slots, clamping profile for cable entry. The two-piece design with cable entry allows for easy retro-fitting.
Material	Carbon steel
Color	RAL 7035
Suitable for	Enclosure type: TS TS IT Width: 800 mm Depth: 1,000 mm Enclosure type: TS TS IT Width: 31.5 " Depth: 39.4 "
Packaging unit	1 pc(s).
Net weight	10.7 kg
Gross weight	14.5 kg
Customs tariff number	73269098
ETIM 9	EC000744
ECLASS 8.0	27182405
Product description	DK-TS8 Roof plate, WxD: 800x1000 mm, 2-part, For cable entry