

Rittal – The System.

Faster – better – everywhere.



DK 7856.713

Mounting frame, 482.6 mm (19")

State: 7/31/2025 (Source: [rittal.com/us-en](https://www.rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES


FRIEDHELM LOH GROUP



DK 7856.713 - Mounting frame, 482.6 mm (19") for TS, CS

Basic and modular enclosures

To extend the front and rear 482.6 mm (19") level, the welded 482.6 mm (19") mounting frame can be fastened at variable depths.

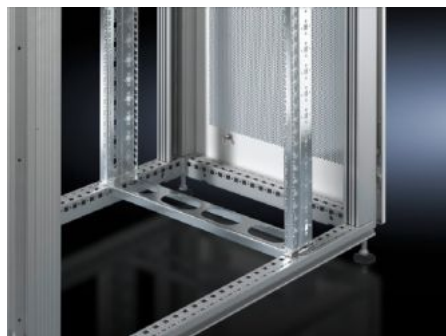

Features

Model No.	DK 7856.713
Product description	The welded 482.6 mm (19") mounting frame can be secured at variable depths and is used to lay out the front and rear 482.6 mm (19") level. The mounting frame has TS enclosure profile system punchings on the side and at the rear, to allow TS system accessories such as cable clamp rails, cable routing brackets, etc. to be mounted.
Material	Carbon steel
Surface finish	Zinc-plated
Supply includes	Assembly components
Dimensions	Width: 482.6 mm Width: 19 "
Height units	24 U
Load capacity	Up to 10,000 N static load, with even load distribution on two 482.6 mm (19") mounting frames, with full installation.
Note	A combination of 482.6 mm (19") mounting frame plus fan mounting plate is not possible. For active ventilation, we recommend using with the modular fan roof.

Features

Suitable for	Enclosure type: TS 8 CS basic housings CS Modular Enclosures Width: 600 mm Height: 1,200 mm Enclosure type: TS 8 CS basic housings CS Modular Enclosures Width: 23.6 " Height: 47.2 "
Packaging unit	1 pc(s).
Net weight	7.631
Gross weight	8.033
Customs tariff number	73269098
EAN	4028177402355
ETIM 9	EC002620
ECLASS 8.0	27189261