
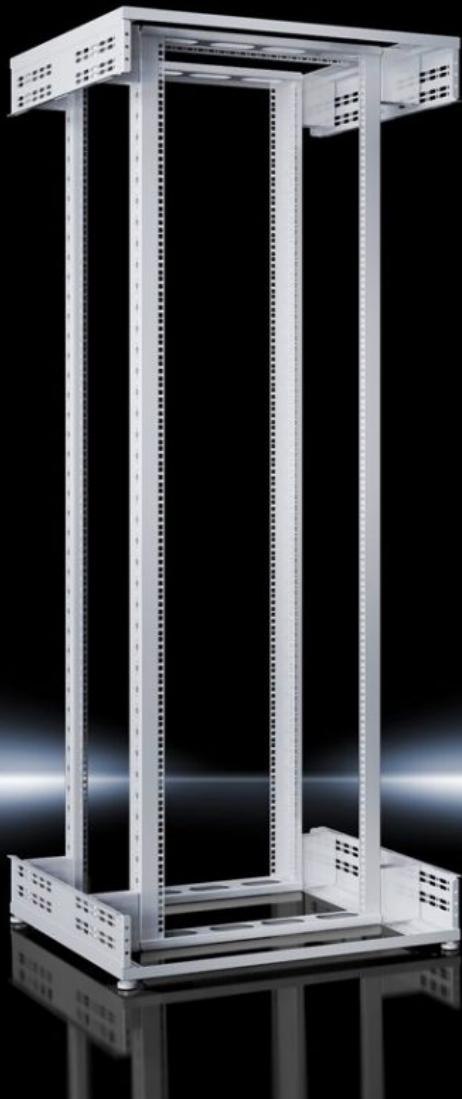


Rittal – The System.

Faster – better – everywhere.

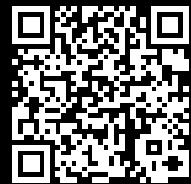

TE 7888.940

Distributor Racks

State: 2/17/2026 (Source: ittal.com/us-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TE 7888.940 - Distributor Racks TE 8000 open

For optimum accessibility from all sides during assembly and installation.

Features

Model No.	TE 7888.940
Benefits	<p>Optimum accessibility from all sides during assembly and installation</p> <p>Unrestricted airflow, due to the open design</p> <p>The distance between mounting levels is infinitely variable</p>
Material	Carbon steel
Surface finish	Powder-coated
General color	RAL 7035
Color	RAL 7035
Supply includes	<p>Self-supporting mounting frame, with 482.6 mm (19") mounting level front and rear</p> <p>Roof-plate, prepared for accommodating a cable organizer</p> <p>Open base frame with 2 system chassis for individual configuration fitted in the width</p> <p>4 leveling feet, M10 (supplied loose)</p> <p>Roof plate with horizontal brush strip at rear</p>
Dimensions	<p>Width: 600 mm</p> <p>Height: 2,000 mm</p> <p>Depth: 1,000 mm</p> <p>Width: 23.6 "</p> <p>Height: 78.7 "</p> <p>Depth: 39.4 "</p>
Height units	42 U
Height units	42 U
Mounting space to 19" level, front/ rear	80 mm / 130 mm
Distance between levels as delivered	<p>745 mm</p> <p>29.3 "</p>

Features

Load capacity	7,000 N
Base material	Carbon steel
Packaging unit	1 pc(s).
Net weight	33 kg
Gross weight	35 kg
Customs tariff number	94032080
ETIM 9	EC002507
ECLASS 8.0	27180602
Product description	TE Network enclosure TE 8000, WHD: 600x2000x1000 mm, 42 U, open